


DF3110



Distribution module for ground potential

Pot.Module GND/10x 2.5mm²

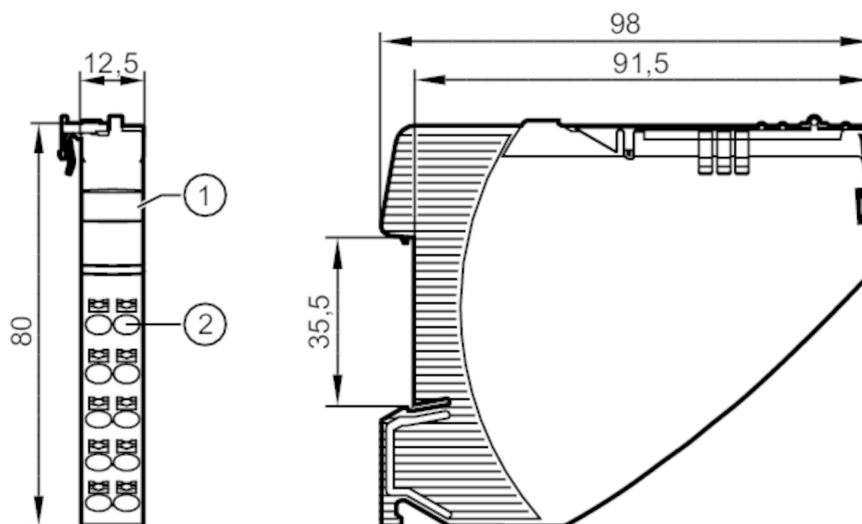

- 1 panel for labelling
2 push-in terminal 24 V DC



Application

Design potential module GND (10 x 2,5 mm²)

Electrical data

Operating voltage [V]	18...30 DC
Nominal voltage DC [V]	24
Protection class	III
Max. load current [A]	20

Operating conditions

Ambient temperature [°C]	-25...60
Storage temperature [°C]	-40...70
Protection	IP 20

Tests / approvals

EMC	EN 61000-6-3	radiation of interference
	EN 61000-6-2	immunity

Mechanical data

Weight [g]	62.5
Type of mounting	mounting on DIN rail
Installation instruction	string mounting possible
Dimensions [mm]	80 x 12.5 x 98.5

DF3110



Distribution module for ground potential

Pot.Module GND/10x 2.5mm²

Electrical connection

push-in terminals:

Connection

