


## Connecting cable with socket

ADOAH032ZDS0005A03

Article no longer available - archive entry

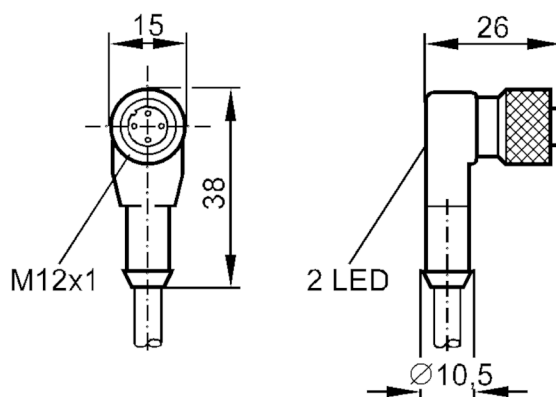

## Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
|-------------------|-----|------------|

## Outputs

|                   |     |
|-------------------|-----|
| Electrical design | PNP |
|-------------------|-----|

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
|---------------------|------|----------|

|            |       |
|------------|-------|
| Protection | IP 67 |
|------------|-------|

## Mechanical data

|            |      |              |
|------------|------|--------------|
| Dimensions | [mm] | 26 x 15 x 38 |
|------------|------|--------------|

|           |     |
|-----------|-----|
| Materials | PUR |
|-----------|-----|

|                       |     |
|-----------------------|-----|
| Moulded-body material | PUR |
|-----------------------|-----|

|              |              |
|--------------|--------------|
| Material nut | diecast zinc |
|--------------|--------------|

## Displays / operating elements

|         |                  |                 |
|---------|------------------|-----------------|
| Display | switching status | 1 x LED, yellow |
|         | operation        | 1 x LED, green  |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E10496



## Connecting cable with socket

ADOAH032ZDS0005A03

### Electrical connection

Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 3 x 0.34 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: diecast zinc



### Connection



|      |                |
|------|----------------|
| BN = | Core colours : |
| BK = | brown          |
| BU = | black          |
|      | blue           |