


E10604



Connection cable


VDOGF030MSS00,6A03STGF030MSS

Article no longer available - archive entry

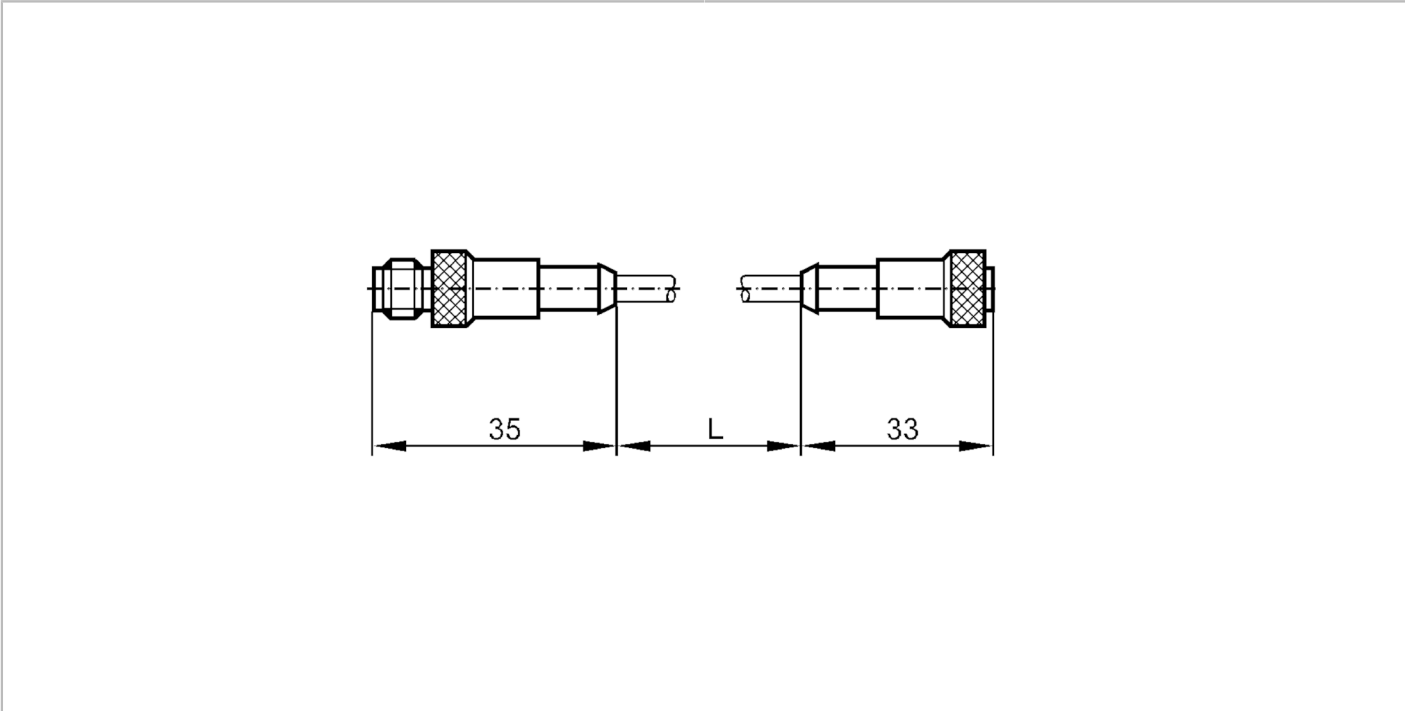

Electrical data		
Operating voltage	[V]	< 60 AC/DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

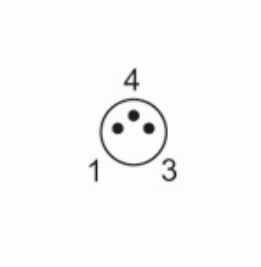

E10604



Connection cable

VDOGF030MSS00,6A03STGF030MSS

Electrical connection

Cable: 0.6 m, PUR / PVC; 3 x 0.25 mm² (128 x Ø 0.05 mm)

Connection



Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: diecast zinc, nickel-plated

