


E10631



Connection cable

VDOAH040ALS0002E03STGH040ALS

Article no longer available - archive entry

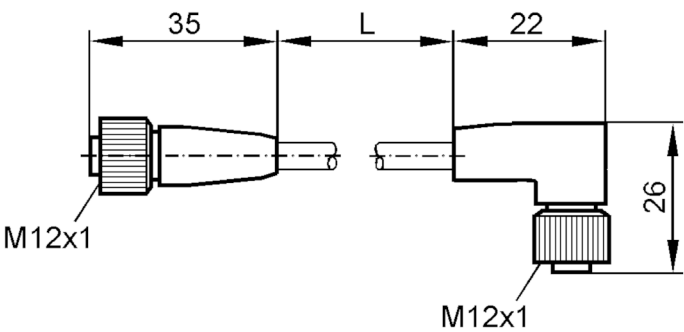

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-20...70
Protection		IP 67

Mechanical data

Materials	PA 6.6
Moulded-body material	PA 6.6
Material nut	diecast zinc, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA 6.6; Locking: diecast zinc, nickel-plated



E10631



Connection cable

VDOAH040ALS0002E03STGH040ALS

Electrical connection

Cable: 2 m, PUR / PVC; 3 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: diecast zinc, nickel-plated

