


E10672



Jumper cable with valve plug

VVSAC041--S0001B03STGH040MSS

Article no longer available - archive entry

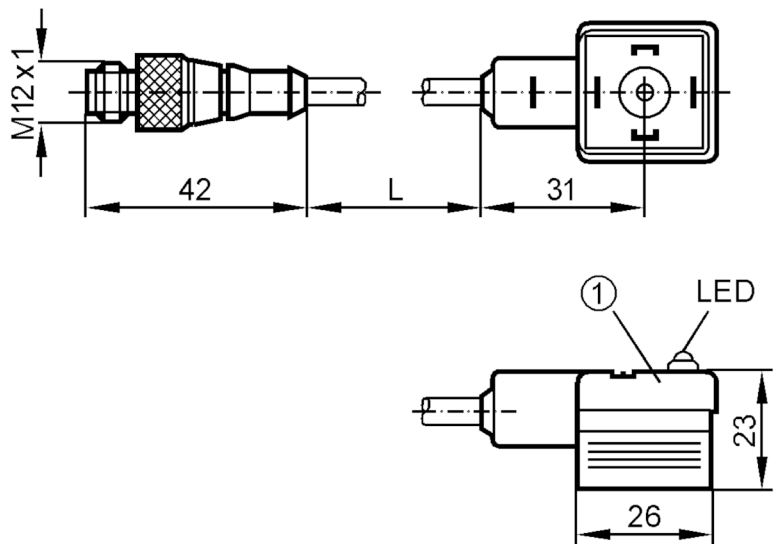

1 grey

Electrical data		
Operating voltage	[V]	< 24 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 65
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
Remarks		
Pack quantity		1 pcs.
Electrical connection - plug		

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated






Jumper cable with valve plug

VVSAC041--S0001B03STGH040MSS

Electrical connection

Cable: 1 m, PUR; 3 x 0.34 mm²

Connection

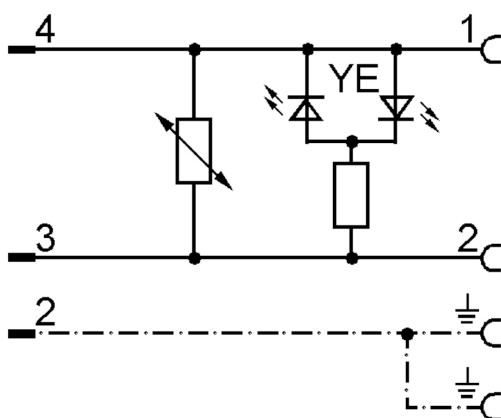

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

