

E10805




Wirable socket

SDOAJ040PLSFKPG

Article no longer available - archive entry

Alternative articles: E10013
When selecting an alternative article and accessories please note that technical data may differ!

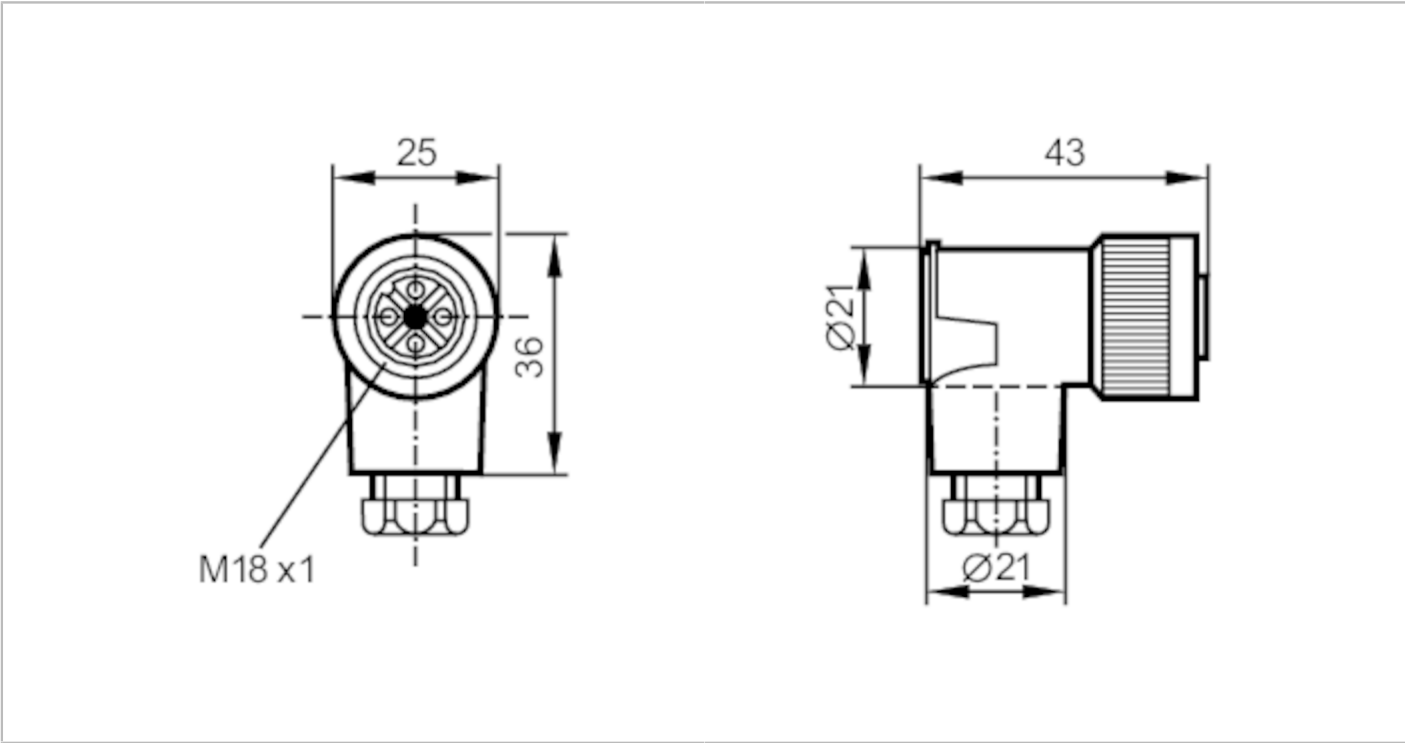

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 65
Mechanical data		
Dimensions	[mm]	43 x 25 x 36
Materials		PBT
Moulded-body material		PBT
Material nut		ULTRAMID
Remarks		
Pack quantity		1 pcs.

E10805



Wirable socket

SDOAJ040PLSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 9

Electrical connection - socket

Connector: 1 x M18, angled; coding: A; Moulded body: PBT; Locking: ULTRAMID; Contacts: gold-plated



Connection

