


Connecting cable with socket

ADOAH043MSS0002H04

Article no longer available - archive entry

Alternative articles: EVC007

When selecting an alternative article and accessories please note that technical data may differ!

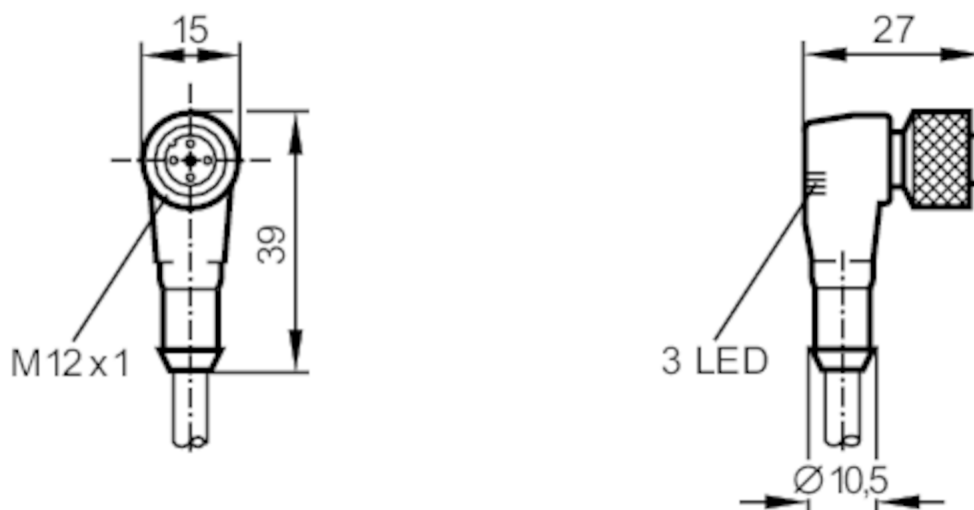

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	27 x 15 x 39
------------	------	--------------

Materials	TPU transparent
-----------	-----------------

Moulded-body material	TPU, transparent
-----------------------	------------------

Material nut	brass, nickel-plated
--------------	----------------------

Displays / operating elements

Display	switching status	2 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E10854



Connecting cable with socket

ADOAH043MSS0002H04

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; 4 x 0.25 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated



Connection

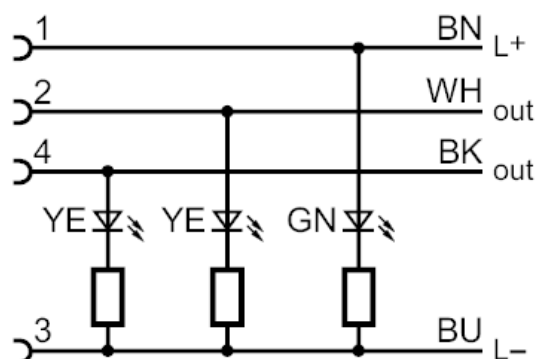

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white