


Connection cable

VDOAF030MSS00,3H03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11324

When selecting an alternative article and accessories please note that technical data may differ!

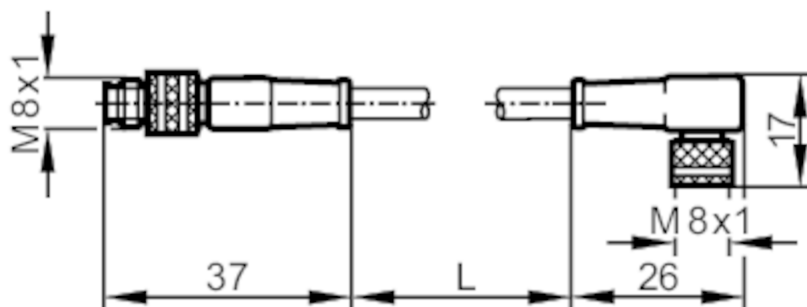

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Protection class	III
------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Remarks

Pack quantity	1 pcs.
---------------	--------



Connection cable

VDOAF030MSS00,3H03STGF030MSS

Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, TPU, Halogen-free; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

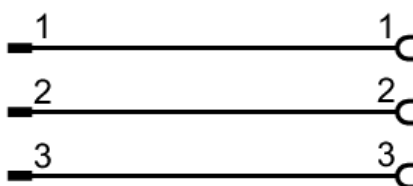

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

