


# E10109



## Wirable socket

SDOGH040PLSFKPG

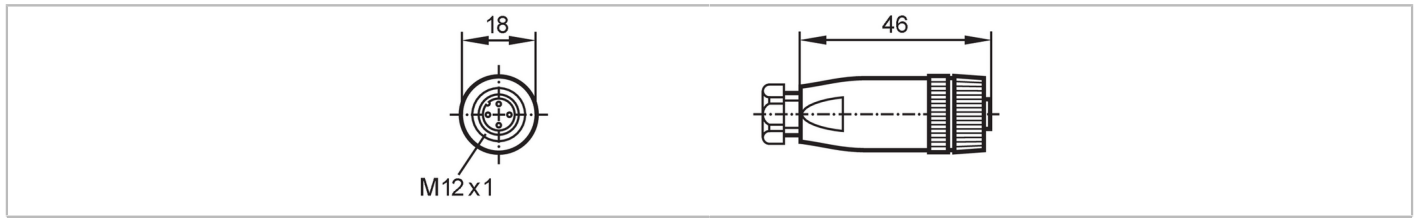

Application	
Application	Industrial applications / factory automation
Electrical data	
Operating voltage [V]	< 250 AC/DC
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-40...85
Protection	IP 67
Mechanical data	
Weight [g]	14.9
Dimensions [mm]	18 x 18 x 46
Moulded-body material	PA
Material nut	PA
Remarks	
Pack quantity	1 pcs.

**Electrical connection**  
screw terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm; AWG 18

**Electrical connection - socket**  
Connector: 1 x M12, straight; coding: B; Contacts: 4, white bronze coated; Moulded body: PA; Locking: PA

