

E10280




Splitter box

ZDO6H057MSS0005H09

Article no longer available - archive entry

Alternative articles: EBC019
When selecting an alternative article and accessories please note that technical data may differ!

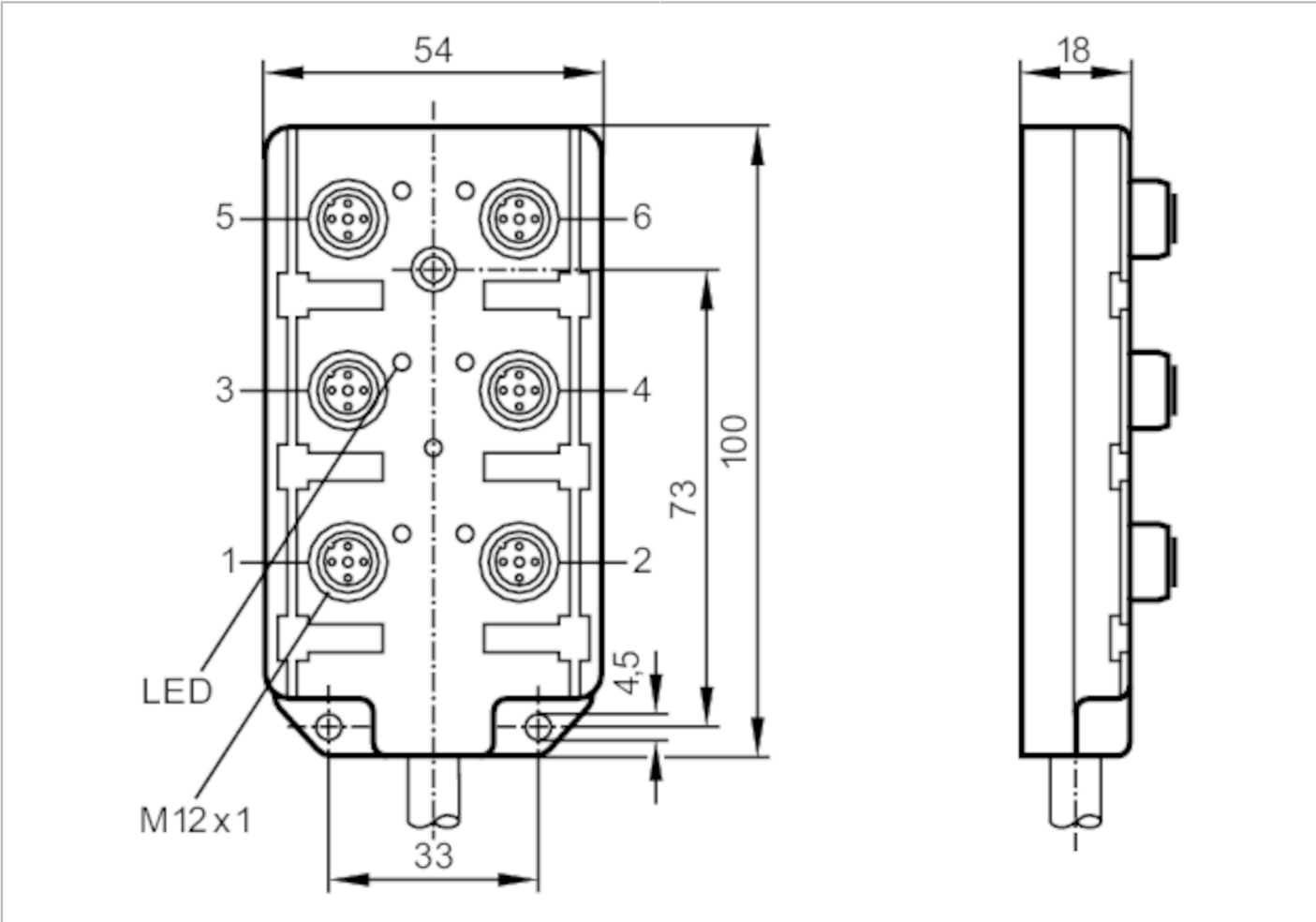

Application		
Special feature	Free from silicone; Halogen-free; Gold-plated contacts	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67
Mechanical data		
Dimensions	[mm]	18 x 54 x 100
Materials		TPU
Moulded-body material		TPU

E10280



Splitter box

ZDO6H057MSS0005H09

Number of ports splitter box	6
Connector type	M12

Displays / operating elements

Display	switching status	6 x LED, yellow
	operation	1 x LED, green

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 9 mm; 6 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 0.75 mm² (95 x Ø 0.1 mm)

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

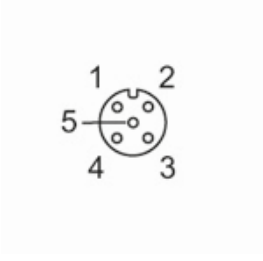


E10280



Splitter box

ZDO6H057MSS0005H09

Connection

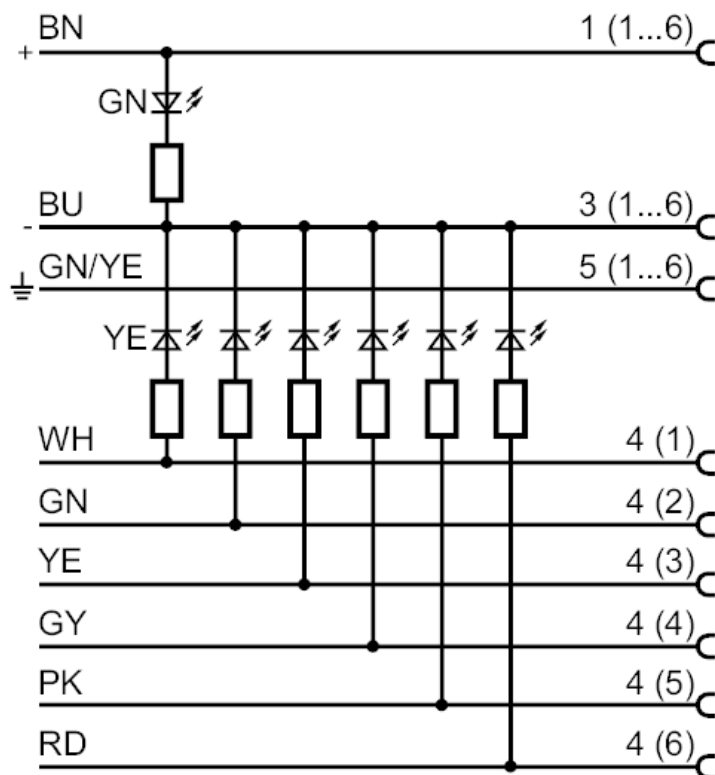

Core colours :
BN = brown
BU = blue
GN = green
GN/YE = green/yellow
GY = grey
PK = pink
RD = red
WH = white
YE = yellow