

# E11861




## Wirable socket

SDOGH040VASFKPG

Article no longer available - archive entry

Alternative articles: EVF565

When selecting an alternative article and accessories please note that technical data may differ!

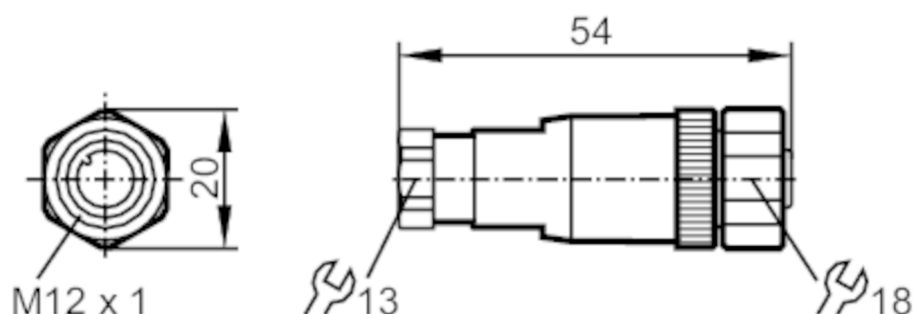

### Application

|                    |                                          |
|--------------------|------------------------------------------|
| Special feature    | Free from silicone; Gold-plated contacts |
| Free from silicone | yes                                      |

### Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 45 AC / < 70 DC |
| Max. current load total | [A] | 4; (...40 °C)     |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

### Mechanical data

|                       |      |                 |
|-----------------------|------|-----------------|
| Weight                | [g]  | 26              |
| Dimensions            | [mm] | 20 x 20 x 54    |
| Materials             |      | PA              |
| Moulded-body material |      | PA              |
| Material nut          |      | stainless steel |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E11861



## Wirable socket

SDOGH040VASFKPG

### Electrical connection

screw terminals: ...0.75 mm<sup>2</sup>; Cable sheath: Ø 4...6 mm

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: stainless steel; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



### Connection

