


E11950



Connecting cable with socket

ADOGH080MSS0002H08

For 8-pole sockets the core colours are not standardised.
Please note the wiring of the sensor and the sockets (see data sheet).

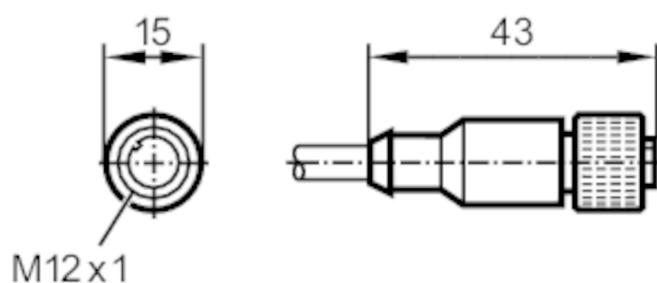

Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 68

Mechanical data

Weight	[g]	135.9
Dimensions	[mm]	15 x 15 x 43
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11950



Connecting cable with socket

ADOGH080MSS0002H08

Electrical connection

Cable: 2 m, PUR, black, Ø 6.2 mm; 8 x 0.25 mm²

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm



Connection

1	BN
2	WH
3	BU
4	BK
5	GY
6	PK
7	VT
8	OG

colours to DIN EN
60947-5-2

Core colours :

BK =	black
BN =	brown
BU =	blue
GY =	grey
PK =	pink
OG =	orange
VT =	lilac
WH =	white