




Connection cable

VDOGH080MSS01,5A06STGH080MSS

Article no longer available - archive entry

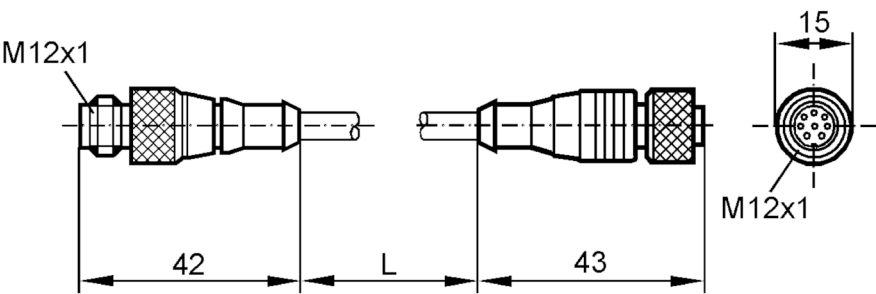

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data	
Operating voltage	[V] 10...30 DC


Operating conditions	
Ambient temperature	[°C] -25...85
Protection	IP 67

Mechanical data	
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Remarks	
Pack quantity	1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

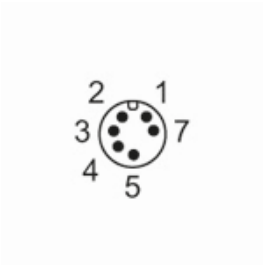




Connection cable

VDOGH080MSS01,5A06STGH080MSS

Electrical connection

Cable: 1.5 m, PUR / PVC, Halogen-free; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

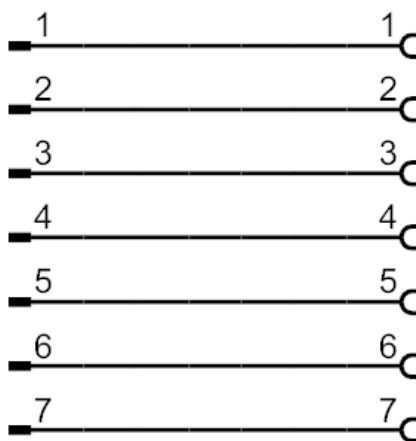

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm

