

Connection cable

VDOGF040MSS00,2H04STGF040MSS

Article no longer available - archive entry



Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 65; IP 67

Mechanical data

Weight	[g]	20.6
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------



Connection cable

VDOG F040MSS00,2H04STGF040MSS

Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Electrical connection

Cable: 0.2 m, PUR, black, Ø 4.4 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

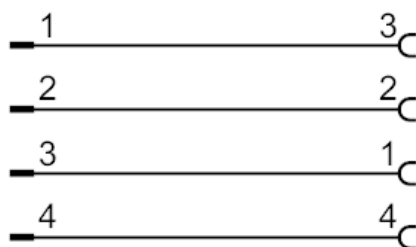

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

