


E12334



Connecting cable with socket

ADOAH040MSS0015C04

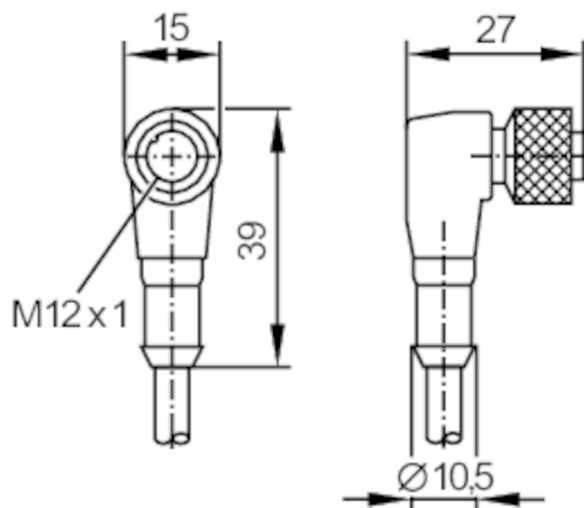

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Screened cable
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 50 AC / < 60 DC
Protection class		III
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	0.001
Dimensions	[mm]	27 x 15 x 39
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E12334



Connecting cable with socket

 
ADOAH040MSS0015C04

Electrical connection


Cable: 15 m, PUR, Halogen-free, black, Ø 5 mm, shielded; 4 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm; Shielded connection cable: screen connected



Connection

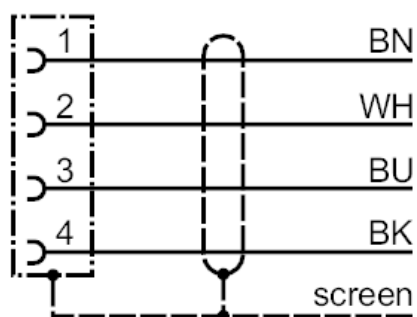

BK =	Core colours :	black
BN =		brown
BU =		blue
WH =		white