




Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,12M

Article no longer available - archive entry

Alternative articles: E20569

When selecting an alternative article and accessories please note that technical data may differ!

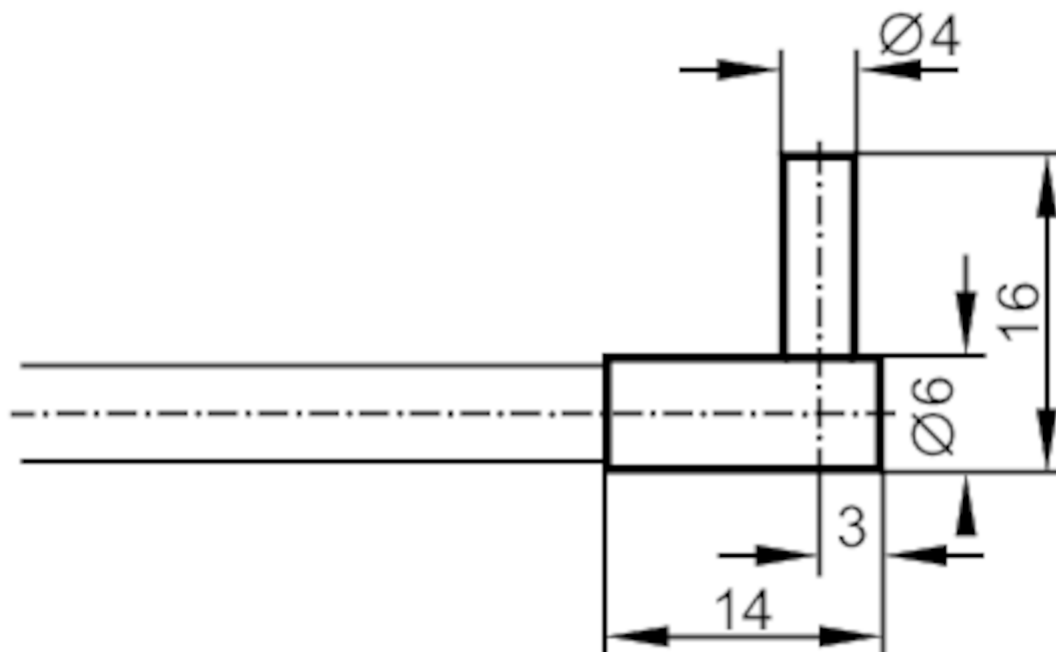

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

4

Sensing head length

[mm]

10

Total length

[mm]

120

E20407



Fibre optic diffuse reflection sensor

FT-00-P-A-R4/0,12M

Min. bending radius	[mm]	20
Materials	Adapter: PPE	
Fibre material	glass	
Fibre head material	aluminium	
Fibre sheath material	PVC	
Remarks		
Pack quantity	1 pcs.	