


Fibre optic diffuse reflection sensor

FT-00-A-V-E1/0,25M

Article no longer available - archive entry

Alternative articles: E20057

When selecting an alternative article and accessories please note that technical data may differ!

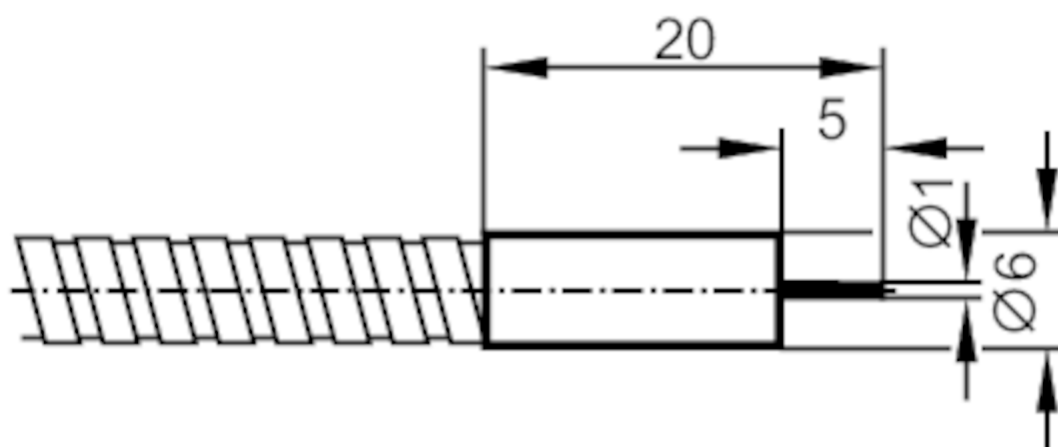

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

8

OUF

Range fibre optics

[mm]

8

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

1

Sensing head length

[mm]

5

Total length

[mm]

250

E20410



Fibre optic diffuse reflection sensor

FT-00-A-V-E1/0,25M

Min. bending radius	[mm]	20
Materials	Adapter: ABS	
Fibre material	glass	
Fibre head material	stainless steel (1.4305 / 303)	
Fibre sheath material	aluminium	
Remarks		
Pack quantity	1 pcs.	