




Fibre optic through-beam sensor

FE-00-P-A-R3/S

Article no longer available - archive entry

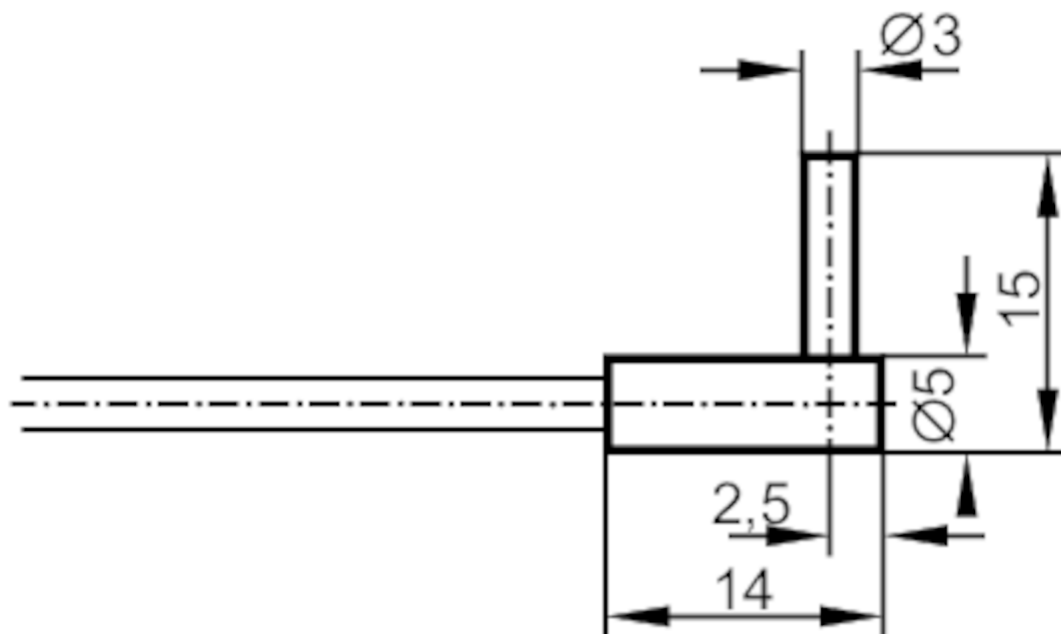

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

80

OUF

Range of fibre optics

[mm]

80

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

175; (-5 mm)

Min. bending radius

[mm]

20

Materials

Adapter: PPE

Fibre material

glass

E20497



Fibre optic through-beam sensor

FE-00-P-A-R3/S

Fibre head material	aluminium
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.