


Fibre optic diffuse reflection sensor

FT-18-A-A-M6/1M

Article no longer available - archive entry

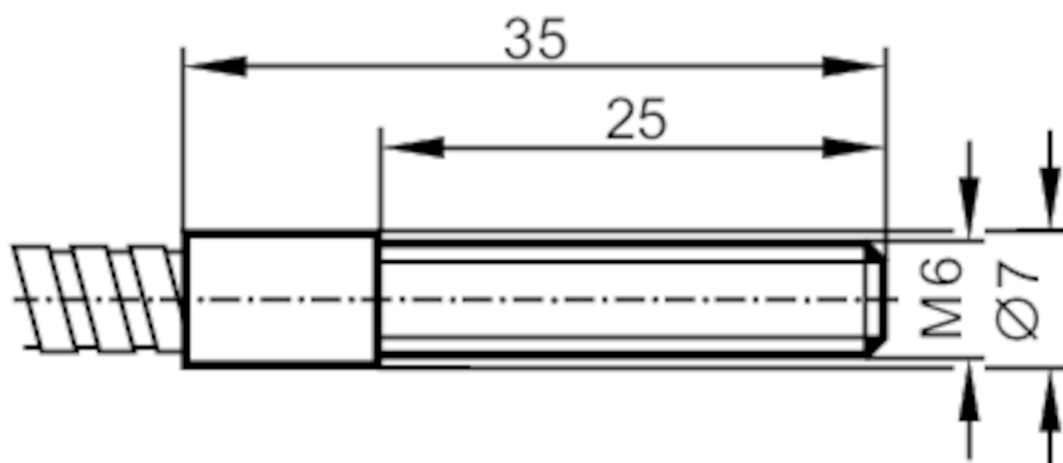

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OGF

OGF

Range fibre optics

[mm]

15

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

25

Total length

[mm]

1000

Min. bending radius

[mm]

20

Materials

Adapter: PPE

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

PVC

E20742



Fibre optic diffuse reflection sensor

FT-18-A-A-M6/1M

Remarks	
Pack quantity	1 pcs.