


Fibre optic diffuse reflection sensor

FT-00-P-A-E3/S 0,8m

Article no longer available - archive entry

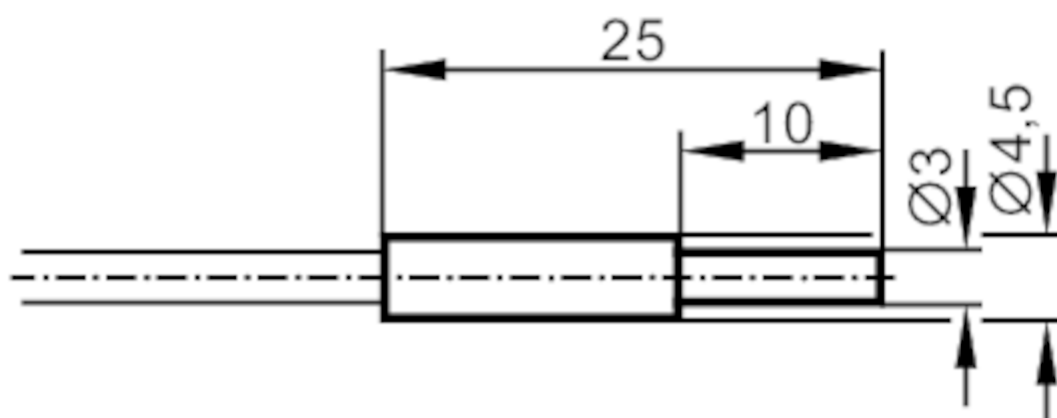

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic
amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

25

Total length

[mm]

800

Min. bending radius

[mm]

20

Materials

Adapter: PPE

Fibre material

glass

E20095



Fibre optic diffuse reflection sensor

FT-00-P-A-E3/S 0,8m

Fibre head material	aluminium
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.