




Fibre optic diffuse reflection sensor

FT-00-P-A-R4/1M

Article no longer available - archive entry

Alternative articles: E20054

When selecting an alternative article and accessories please note that technical data may differ!

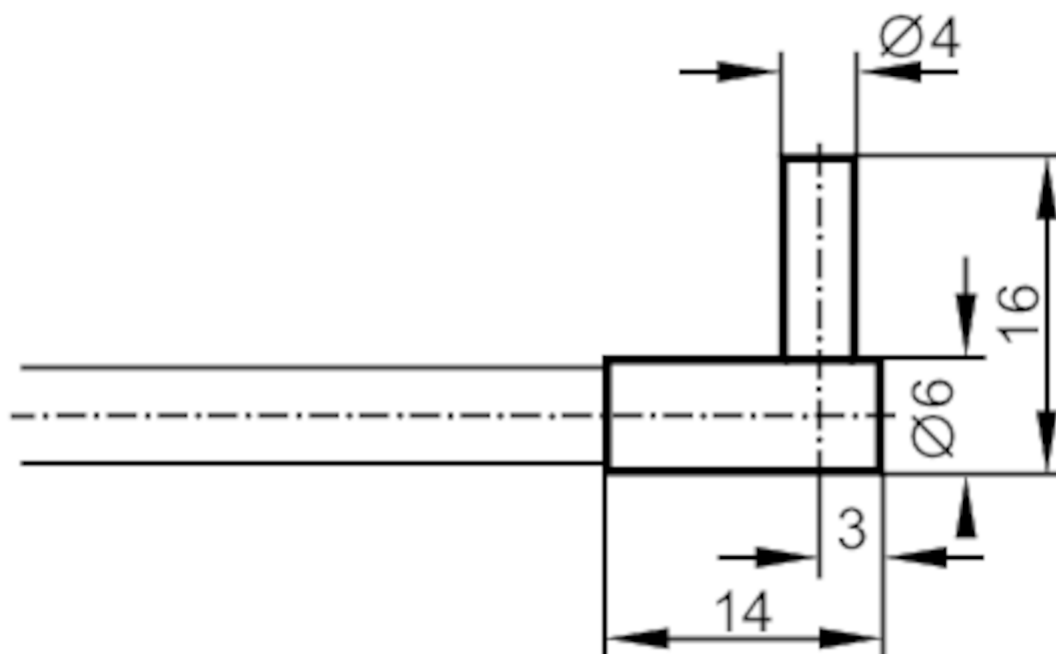

Application

Function principle Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type OKF; OUF

OKF

Range fibre optics [mm] 40

OUF

Range fibre optics [mm] 40

Operating conditions

Ambient temperature [°C] -20...80

Mechanical data

Version of sensing head angled

Sensing head diameter [mm] 4

Sensing head length [mm] 10

Total length [mm] 1000

E20120



Fibre optic diffuse reflection sensor

FT-00-P-A-R4/1M

Min. bending radius	[mm]	20
Materials	Adapter: PPE	
Fibre material	glass	
Fibre head material	aluminium	
Fibre sheath material	PVC	
Remarks		
Pack quantity	1 pcs.	