


Fibre optic through-beam sensor

FE-30-A-A-E3/3M

Article no longer available - archive entry

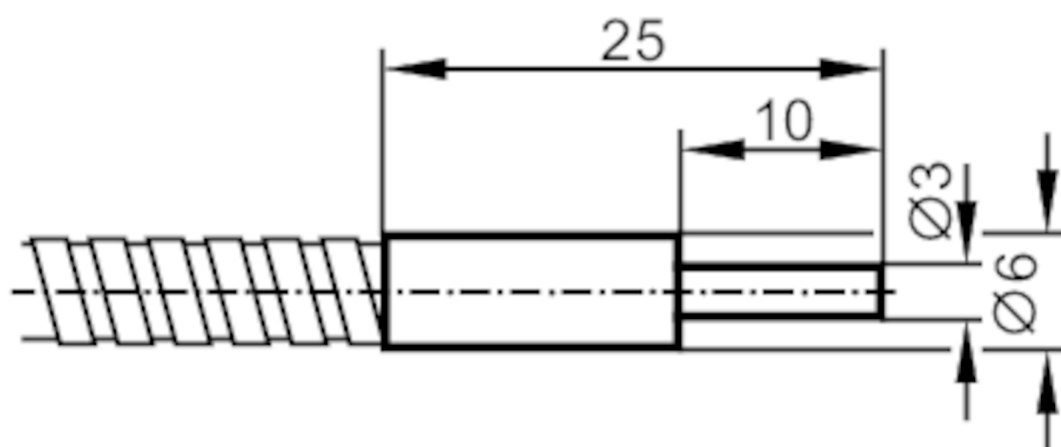

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic amplifier type

OIF

OIF

Range of fibre optics

[mm]

64

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Total length

[mm]

3000

Min. bending radius

[mm]

30

Materials

Adapter: PA

Fibre material

glass

Fibre head material

aluminium

Fibre sheath material

aluminium

E20347



Fibre optic through-beam sensor

FE-30-A-A-E3/3M

Remarks	
Pack quantity	1 pcs.