


# E33408



## Process adapter pipe fitting DIN 11864

ADAPT DIN 11864-1-BS-A/DN40/G1/2

Article no longer available - archive entry

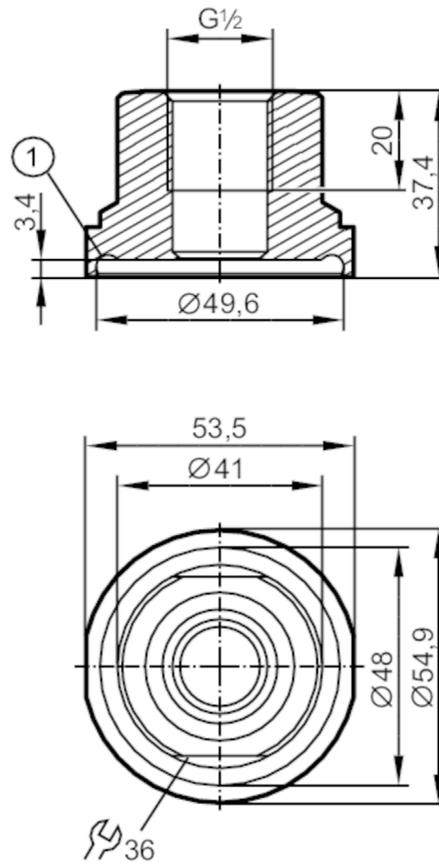

1 groove for O-ring DIN 11864-R-40x5

**EHEDG** Tested 

Application	
Design	for pipes DN 40 (DIN 11866, Reihe A)
Pressure rating [bar]	40
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Standard	DIN 11864-BS-A-41x1,5-1.4435-H3
Mechanical data	
Weight [g]	399
Materials	stainless steel (316L/1.4435)
Sensor connection	G 1/2 sealing cone
Process connection	Pipe fitting DN40 DIN 11864-1-A-BS
Surface characteristics Ra/Rz of the wetted parts	0.4 / 4
Hygienic equipment class to DIN 11866	H3

# E33408



## Process adapter pipe fitting DIN 11864

ADAPT DIN 11864-1-BS-A/DN40/G1/2

Accessories	
Items supplied	O-ring:, FKM
Remarks	
Pack quantity	1 pcs.