

Process adapter pipe fitting DIN 11864


ADAPT IFM-DIN11864-1A / DN40

Article no longer available - archive entry

Alternative articles: E33302

When selecting an alternative article and accessories please note that technical data may differ!

The alternative article requires the use of a new sensor with Aseptoflex Vario external thread

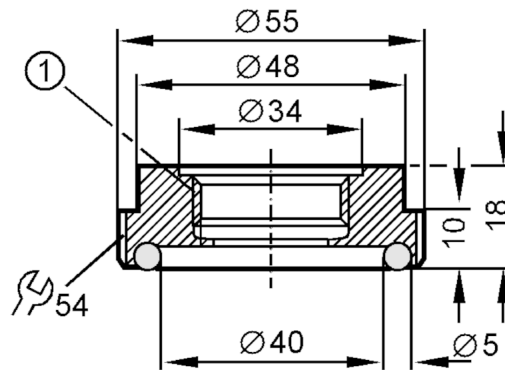

1 Aseptoflex thread

EC 1935/2004 

Application

Pressure rating [bar] 25

Tests / approvals

Pressure Equipment Directive

A possible classification to PED depends on the application and has to be carried out by the user / operator.

Safety instructions

The compatibility between medium and product material has to be checked in all applications.

Mechanical data

Weight [g] 224.5

Materials stainless steel (316L/1.4404); O-ring: EPDM

Sensor connection Aseptoflex

Process connection Pipe fitting DN40 DIN 11864-1-A-BS

Surface characteristics Ra/Rz of the wetted parts 0.4 / 4

Hygienic equipment class to DIN 11866 H4

Remarks

Pack quantity 1 pcs.