




Thermowell for temperature sensors

THERMOWELL, D6/1/2"NPT/L=100

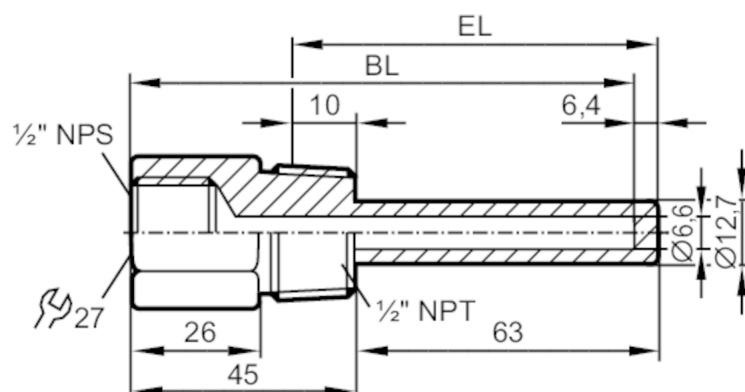

Application

Design for temperature sensors EL = 100 mm

Pressure rating [bar] 400

Accuracy / deviations

Max. permissible flow velocity [m/s] 45

Mechanical data

Weight [g] 180.5

Materials stainless steel (1.4404 / 316L)

Sensor connection 1/2" NPS Ø 6 mm suitable for G1/2 and 1/2" NPT

Process connection 1/2" NPT

Installation length EL [mm] 74

Bore length BL [mm] 101.6

Remarks

Pack quantity 1 pcs.