


E43245



Coaxial pipe for level sensors

LR COAX TUBE G3/4 L1000/2BORES

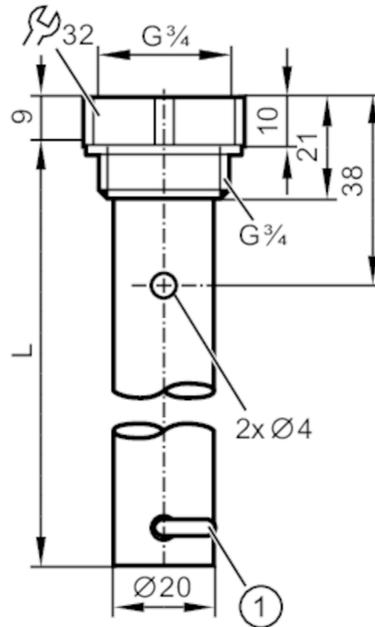

1 fixing bracket for centring piece

Application

Design	Version without holes, for level sensors, LR	
Medium temperature	[°C]	-40...200
Pressure rating	[bar]	16
Vacuum resistance	[mbar]	-1000

Mechanical data

Weight	[g]	600
Materials	Coaxial pipe: stainless steel (304/1.4301); Sealing: NBR reinforced fibre; Centring piece: PPS reinforced fibre; fixing bracket: stainless steel (301/1.4310)	
Sensor connection	threaded connection G 3/4 internal thread	
Process connection	threaded connection G 3/4 external thread	
Length L	[mm]	1000

Accessories

Items supplied	Sealing: 1	
Accessories (optional)	Centring piece for coaxial pipes: 1, E43222	

Remarks

Pack quantity	1 pcs.	
---------------	--------	--