


## Connecting cable with socket

ADOGK120MKR0010B12

Article no longer available - archive entry

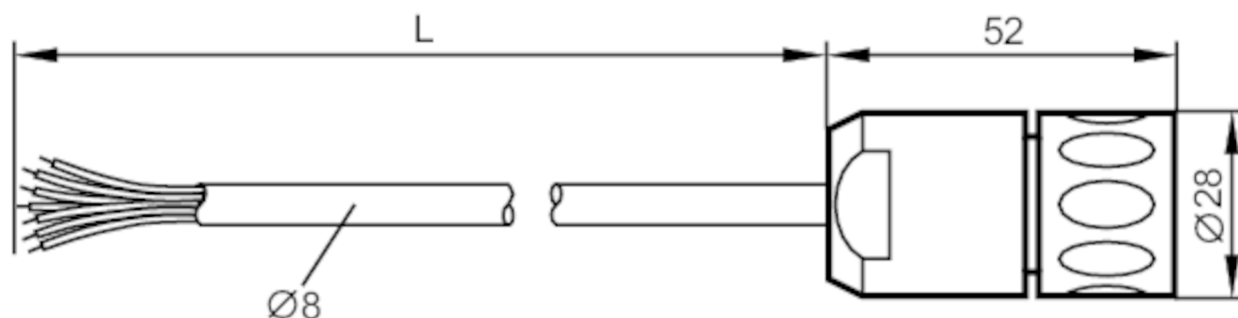

## Electrical data

Operating voltage	[V]	4.5...30 DC
-------------------	-----	-------------

## Operating conditions

Ambient temperature	[°C]	-25...80
---------------------	------	----------

Protection		IP 67
------------	--	-------

## Mechanical data

Weight	[g]	957.2
--------	-----	-------

Dimensions	[mm]	28 x 28 x 52
------------	------	--------------

Materials		brass in plastic sheath; PA 6.6 black
-----------	--	---------------------------------------

Moulded-body material		brass / PA 6.6, in plastic sheath
-----------------------	--	-----------------------------------

Material nut		brass, in plastic sheath / PA 6.6, in plastic sheath
--------------	--	--

## Remarks

Pack quantity		1 pcs.
---------------	--	--------

# E60147



## Connecting cable with socket

ADOGK120MKR0010B12


### Electrical connection

Cable: 10 m, PUR, Ø 8 mm; 8 x 0.14 mm² + 4 x 0.5 mm²

### Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

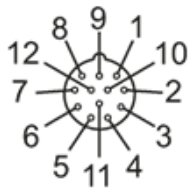

### Connection

1	PK
2	BU
3	RD
4	BK
5	BN
6	GN
7	VT
8	GY
9	n.c.
10	WH/GN
11	WH
12	BN/GN

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white