


E60190



Connecting cable with socket

ADOGK170MSL005B17

Article no longer available - archive entry

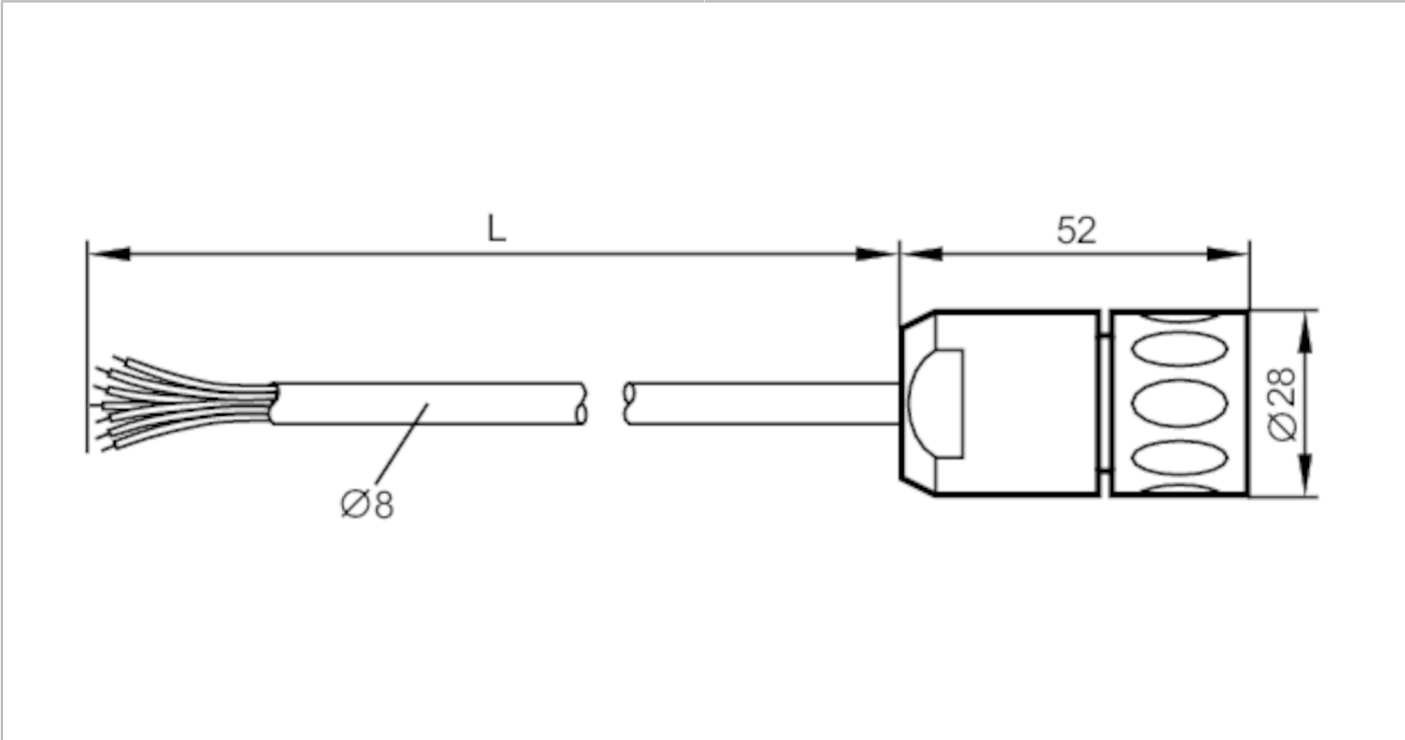

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-10...85
Protection		IP 67
Mechanical data		
Weight	[g]	550
Dimensions	[mm]	28 x 28 x 52
Materials		brass in plastic sheath; PA 6.6 black
Moulded-body material		brass / PA 6.6, in plastic sheath
Material nut		brass, in plastic sheath / PA 6.6, in plastic sheath
Remarks		
Pack quantity		1 pcs.

E60190



Connecting cable with socket

ADOGK170MSL005B17


Electrical connection

Cable: 5 m, PUR, Ø 8 mm; 13 x 0.14 mm² + 4 x 0.5 mm²

Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

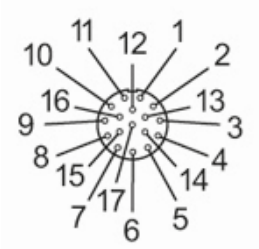

Connection

1	BU
2	BK
3	RD
4	WH
5	GN
6	BN
7	BN/GN
8	VT
9	YE
10	WH/GN
11	screen
12	BU/BK
13	RD/BK
14	GY
15	GN/BK
16	YE/BK
17	PK

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow
screen =	screen