


AS-Interface flat cable insulation displacement connector

FC Splitter ASI M12 FCbottom

Article no longer available - archive entry

Alternative articles: E70586

When selecting an alternative article and accessories please note that technical data may differ!

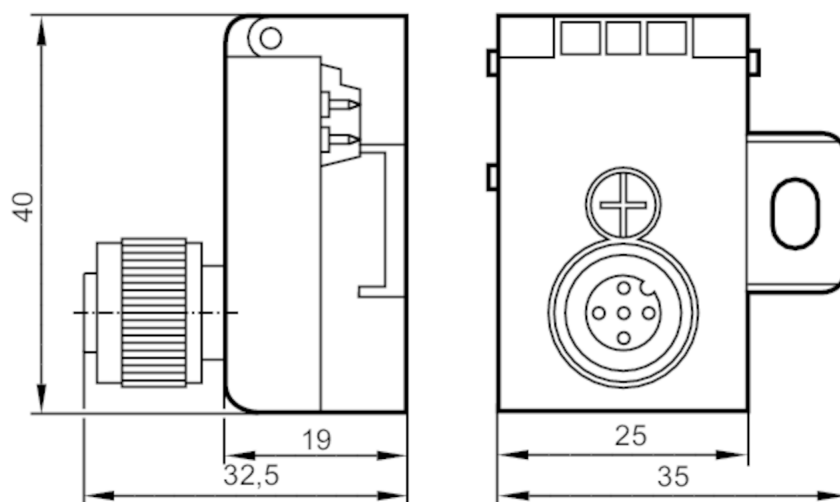

Outputs

Electrical design	AS-i
-------------------	------

Operating conditions

Ambient temperature	[°C]	-25...75
Protection		IP 67

Mechanical data

Weight	[g]	39.1
Type of mounting		keyway top right
Dimensions	[mm]	40 x 32.5 x 35
Materials		PA 6.6-GF25
Tightening torque	[Nm]	< 1.65

Accessories

Accessories (optional)	flat cable end seal:, E70413
	heat-shrink cap:, E70113

Remarks

Remarks	The flat cable should not end in the splitter. Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.




AS-Interface flat cable insulation displacement
connector

FC Splitter ASI M12 FCbottom

Electrical connection

Connector: M12; coding: A

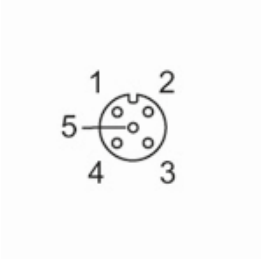

Connection	
1	AS-i +
3	AS-i -
keyway top right	