




Connection cable

VVDAB031--S0015A03STAH030MSS

Article no longer available - archive entry

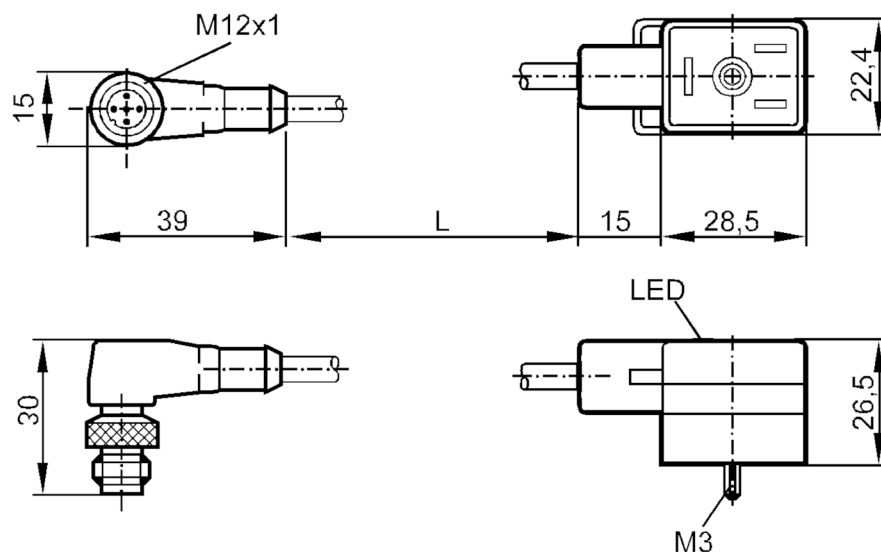

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection		IP 67
------------	--	-------

Mechanical data

Dimensions	[mm]	15 x 30 x 39
------------	------	--------------

Materials		PUR
-----------	--	-----

Moulded-body material		PUR
-----------------------	--	-----

Material nut		brass, nickel-plated
--------------	--	----------------------

Accessories


Items supplied		screw panel for labelling
----------------	--	------------------------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug

 Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E70006




Connection cable

VVDAB031--S0015A03STAH030MSS

Electrical connection

Cable: 15 m, PUR / PVC; 2 x

Connection

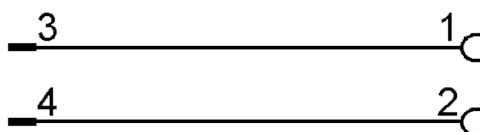

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

