




Touch Panel PC

Panel PC FT-11.6/Celeron/4GB/128GB

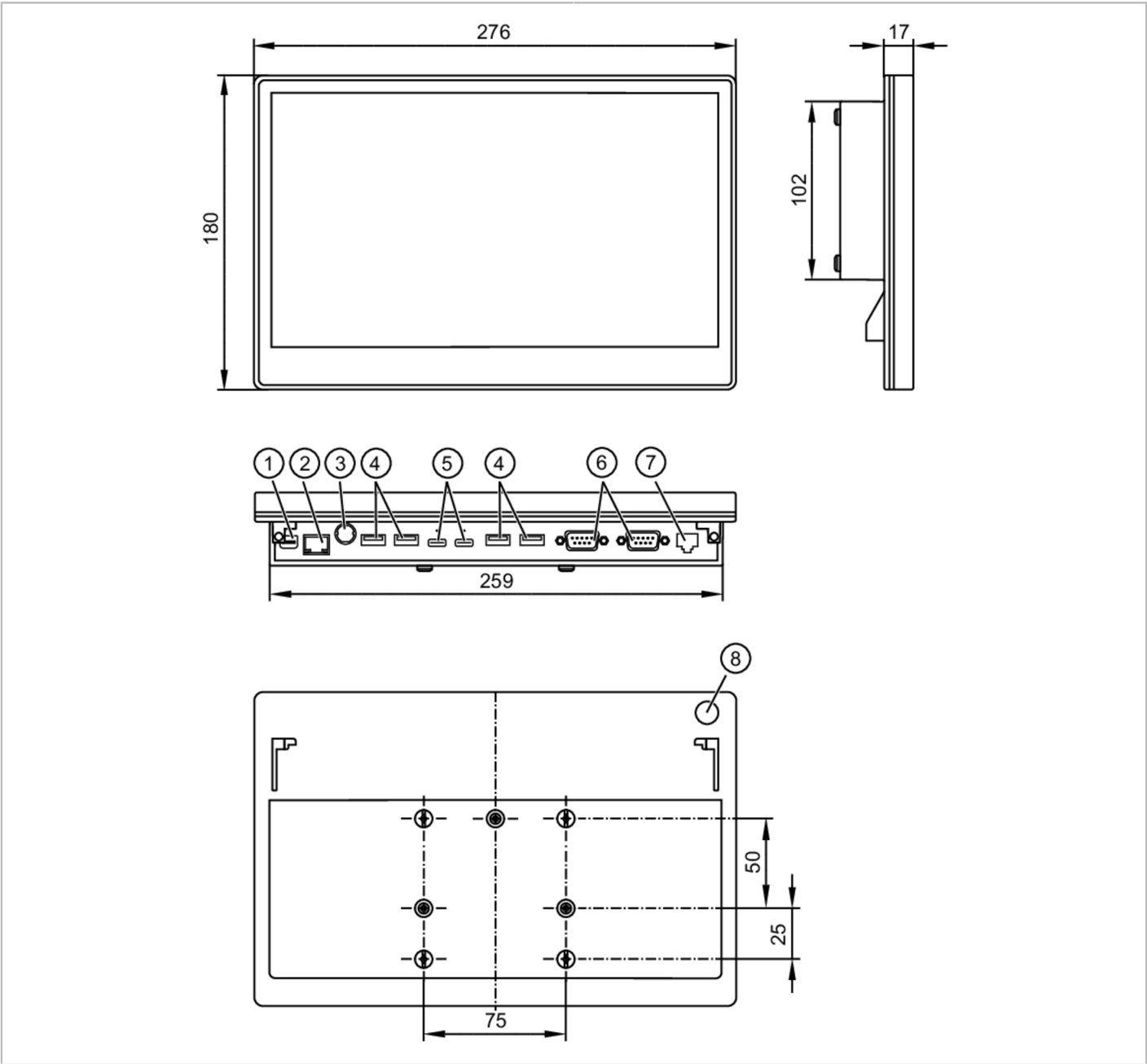

Electrical data		
Operating voltage	[V]	19 DC; (Power supply 230AC / 19DC)
Power consumption	[W]	65
Outputs		
Number of video outputs		1; (Proprietary miniDP)
Software / programming		
Operating system		Windows 10 IoT Enterprise, Linux
Interfaces		
Number of Ethernet interfaces		1; (plug RJ45)
Number of R232 interfaces		2
Number of USB interfaces		6; (USB Type -A 2 x USB 3.0 2 x USB 2.0; USB Type - C 2 x USB 3.0)

ZJF060



Touch Panel PC

Panel PC FT-11.6/Celeron/4GB/128GB

Connector type		RJ11; RJ45	
Operating conditions			
Storage temperature		[°C]	-20...60
Max. relative air humidity		[%]	85; (non condensing)
Protection		IP 54	
Mechanical data			
Weight		[g]	2605.7
Type of mounting		VESA standard; (75 x 75 mm)	
Dimensions		[mm]	277 x 180.5 x 40.8
Displays / operating elements			
Display		colour display	LC display, 1920 x 1080 11,6"
Hardware			
Processor		Intel Elkhart Lake Celeron J6412 2,6 GHz	
RAM		4GB DDR4	
Mass storage		128GB SSD	
Remarks			
Pack quantity		1 pcs.	