


ANT960

RFID-UHF-Antenne

DTRUHFA_AERWKOTN04

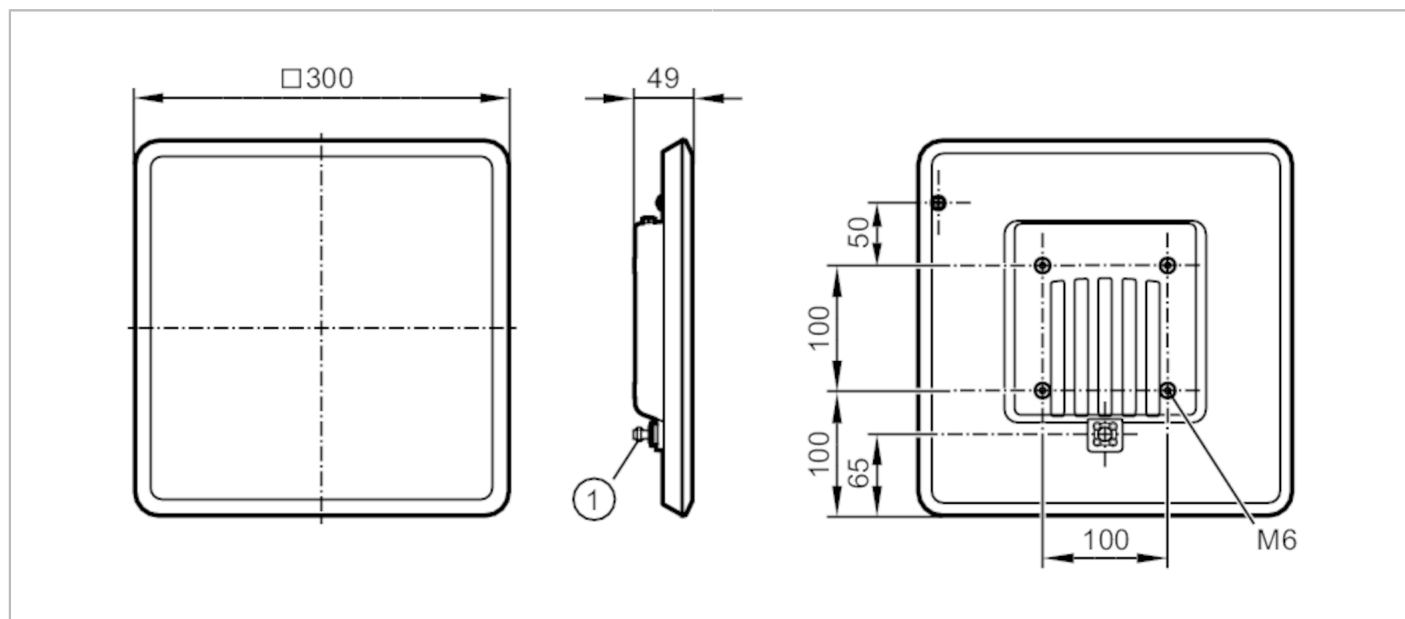

Elektriske Data

Max. input effekt	[mW]	1000
Arbejdsfrekvens	[MHz]	902...928 (FCC)
Antenne forbindelser		1; (TNC-hunstik)
Polarisation		cirkulær
Transmissions effekt ERP	[mW]	3981
Antenne forstærkning	[dB]	8,5
Impedans	[Ω]	50

Registreringsområde

Åbningsvinkel	[°]	65
---------------	-----	----

Omgivende forhold

Omgivelsestemperatur	[°C]	-40...70
Lagringstemperatur	[°C]	-40...85
Kapslingsklasse		IP 67

Mekaniske data

Vægt	[g]	2406,5
Kapsling		rektangulær
Dimensioner	[mm]	300 x 300 x 79
Materiale		Kapsling: aluminium; TNC-hunstik: messing / PTFE (teflon); Beskyttelses afdækning: Kunststof;

Bemærkning

Emballage-enheder		1 stk.
-------------------	--	--------