

MONITOR ANALOGUE VIDEO INPUT/2 PORT





Monitor med to analoge video input

MONITOR ANALOGUE VIDEO INPUT/2 PORT


Mekaniske data	
Vægt	[g] 1342,1
Materiale	Kapsling: ABS sort; fikstur: aluminium sort
Display / Betjeningsenhed	
Display type	farve display
Display størrelse	7"
Bemærkning	
Bemærkning	Spannungsbereich auf dem Typenschild beachten
	Ältere Versionen des Gerätes verwenden einen
	Spannungsbereich von 18...30 VDC (Revisionsnr. AA)
Emballage-enheder	1 stk.
Elektrisk tilslutning - Hunstik	
Kabel: 2 m	
Stik: 2 x M16; kodning: A	
	



Monitor med to analoge video input

MONITOR ANALOGUE VIDEO INPUT/2 PORT

Tilslutning

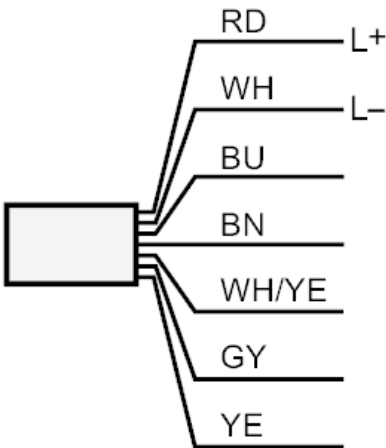

RD:	L+
WH:	L-
BU:	aktivér kamera 1
BN:	aktivér kamera 2
WH/YE:	aktivér kamera 3
GY:	aktivér kamera 4 tachometer
YE:	håndbremse

1	koax kabel kerne video signal
2	koax afskærmning video GND
3	U+
4	0 V