




T-stik tilslutning for pneumatisk kobling

AirBox push-in T-connect 10pcs

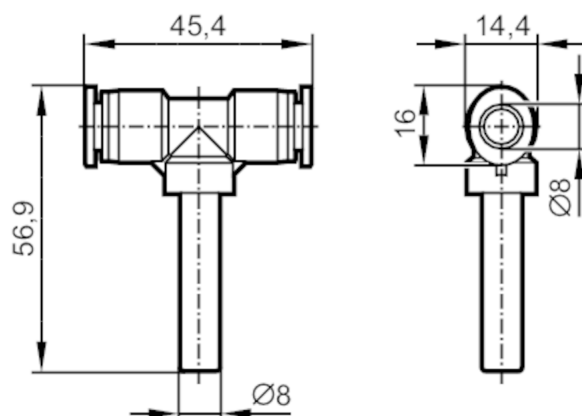

Applikation

Medie

Trykluft iht. ISO 8573-1: 2001

Omgivende forhold

Drifts tryk

[bar]

10; (min. -0,95)

Omgivelsestemperatur

[°C]

-20...80

Mekaniske data

Vægt

[g]

120,1

Materiale

Kapsling: Messing forniklet / PA66; frigivelses ring:
Polyoxymethylen; tandfjederskive: Rustfrit stål; formring: NBR

Slange fittings

8 mm

Kappe diameter

[mm]

8

Bemærkning

Emballage-enheder

10 stk.