




L-hanstik tilslutning for pneumatisk kobling

AirBox push-in L-connect 10pcs

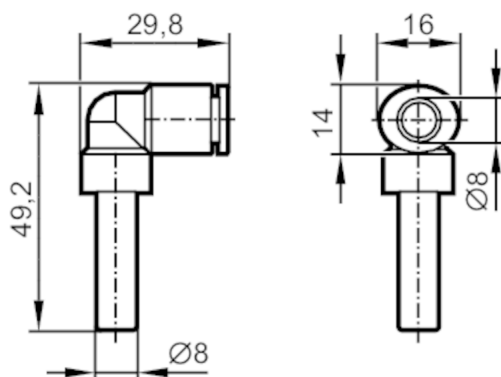

Applikation

Medie	Trykluft iht. ISO 8573-1: 2001
-------	--------------------------------

Omgivende forhold

Drifts tryk	[bar]	10; (min. -0,95)
Omgivelsestemperatur	[°C]	-20...80

Mekaniske data

Vægt	[g]	69,5
Materiale	Kapsling: Messing forniklet / PA66; frigivelses ring: Polyoxymethylen; tandfjederskive: Rustfrit stål; formring: NBR	
Slange fittings		8 mm
Kappe diameter	[mm]	8

Bemærkning

Emballage-enheder	10 stk.
-------------------	---------