




L-hanstik tilslutning for pneumatisk kobling

AirBox push-in L-connector 10 pcs.

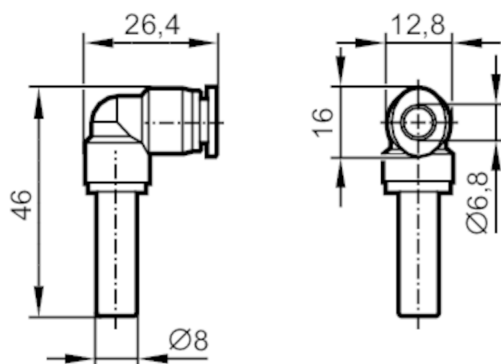

Applikation

Medie

Trykluft iht. ISO 8573-1: 2001

Omgivende forhold

Drifts tryk

[bar]

20; (min. -0,95)

Omgivelsestemperatur

[°C]

-20...80

Mekaniske data

Vægt

[g]

34,5

Materiale

Kapsling: Messing forniklet / PA66; tandfjeder-skive: Rustfrit stål

Slange fittings

6 mm

Kappe diameter

[mm]

8

Bemærkning

Emballage-enheder

10 stk.