


Splitterboks

ZDO4H050MSS0000-00STAK190MSS

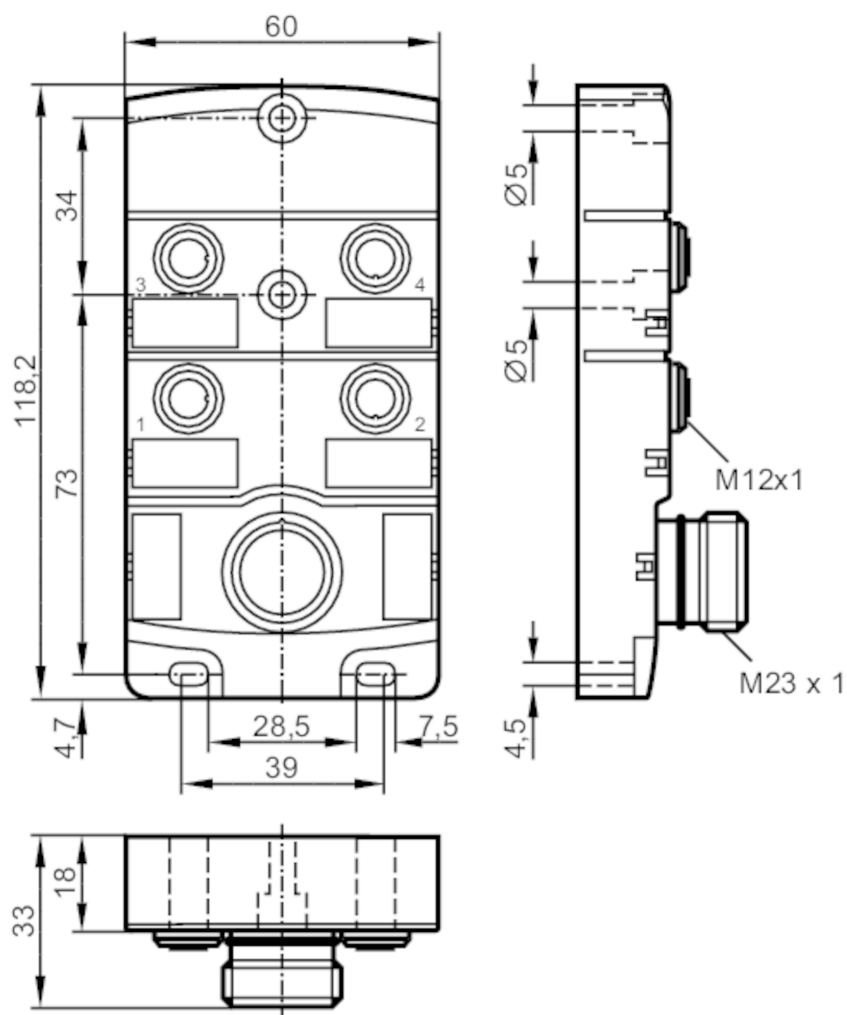

Applikation

Special funktion	Silikonefri; guldbelagte kontakter
Siliconefri	ja

Elektriske Data

Driftspænding [V]	< 30 DC; ("supply class 2" iht. cULus)
Max strømbelastning total pr. modul/slot [A]	4
Max strømbelastning total [A]	10

Omgivende forhold

Omgivelsestemperatur [°C]	-25...80
---------------------------	----------



Splitterboks

ZDO4H050MSS0000-00STAK190MSS

Kapslingsklasse	IP 67
-----------------	-------

Godkendelser / Tests

UL godkendelse	Enclosure type	Type 1
----------------	----------------	--------

Mekaniske data

Vægt [g]	226,5
Dimensioner [mm]	33 x 60 x 118,2
Materiale	PA
Indstøbt-emne materiale	PA
Antal porte på splitterboks	4
Stiktype	M12

Tilbehør


Leverings omfang	Beskyttelseshætte: 2
	mærker: 4

Bemærkning


Emballage-enheder	1 stk.
-------------------	--------

Elektrisk tilslutning - Tilslutning

Stik: 1 x M23; Støbt hus: PA; Kontakter: guldbelagt; tilspændingsmoment: 0,8...1,5 Nm

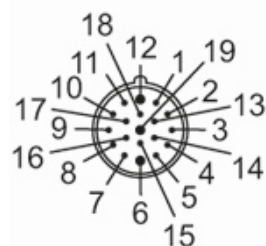

Tilslutning

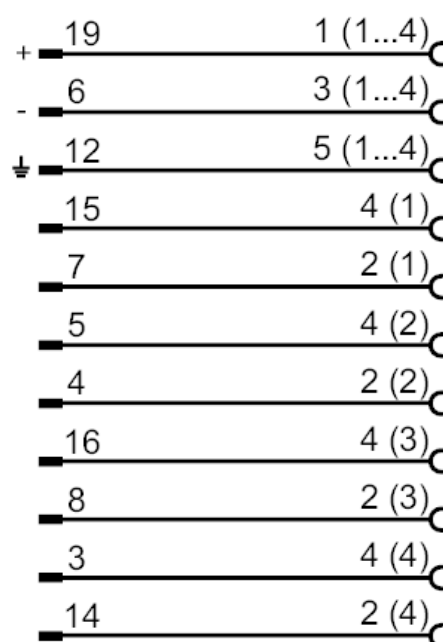



Splitterboks

ZDO4H050MSS0000-00STAK190MSS

Elektrisk tilslutning - slids

Stik: 4 x M12; kodning: A; Støbt hus: PA; Kontakter: guldbelagt; tilspændingsmoment: 0,8...1,5 Nm

