


Splitterboks

ZDO8H050MSS0000-00STAK190MSS

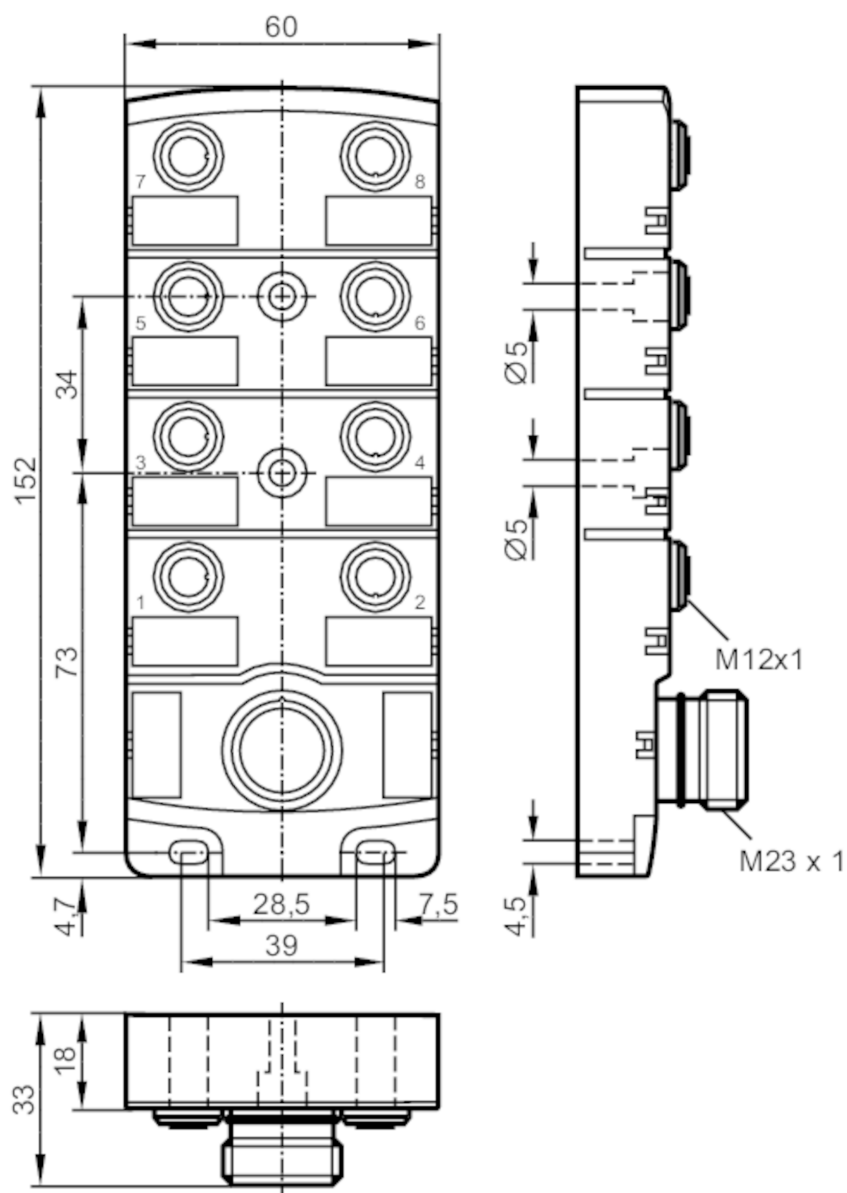

Applikation

Special funktion

Silikonefri; guldbelagte kontakter

Siliconefri

ja

Elektriske Data

Driftspænding

[V]

< 30 DC; ("supply class 2" iht. cULus)

Max strømbelastning total pr. modul/slot

[A]

4

Max strømbelastning total

[A]

10

Omgivende forhold

Omgivelsestemperatur

[°C]

-25...80



Splitterboks

ZDO8H050MSS0000-00STAK190MSS

Kapslingsklasse	IP 67
-----------------	-------

Godkendelser / Tests

UL godkendelse	Enclosure type	Type 1
----------------	----------------	--------

Mekaniske data

Vægt [g]	303,5
Dimensioner [mm]	33 x 60 x 152
Materiale	PA
Indstøbt-emne materiale	PA
Antal porte på splitterboks	8
Stiktype	M12

Tilbehør


Leverings omfang	Beskyttelseshætte: 2
	mærker: 8

Bemærkning

Emballage-enheder	1 stk.
-------------------	--------

Elektrisk tilslutning - Tilslutning

Stik: 1 x M23; Støbt hus: PA; Kontakter: guldbelagt; tilspændingsmoment: 0,8...1,5 Nm

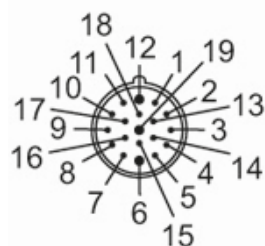

Tilslutning

+	19	1 (1...8)
-	6	3 (1...8)
±	12	5 (1...8)
	15	4 (1)
	7	2 (1)
	5	4 (2)
	4	2 (2)
	16	4 (3)
	8	2 (3)
	3	4 (4)
	14	2 (4)
	17	4 (5)
	9	2 (5)
	2	4 (6)
	13	2 (6)
	11	4 (7)
	10	2 (7)
	1	4 (8)
	18	2 (8)



Splitterboks

ZDO8H050MSS0000-00STAK190MSS

Elektrisk tilslutning - slids

Stik: 8 x M12; kodning: A; Støbt hus: PA; Kontakter: guldbelagt; tilspændingsmoment: 0,8...1,5 Nm

