


ZDO8H05HMSS0000-00STAK190MSS

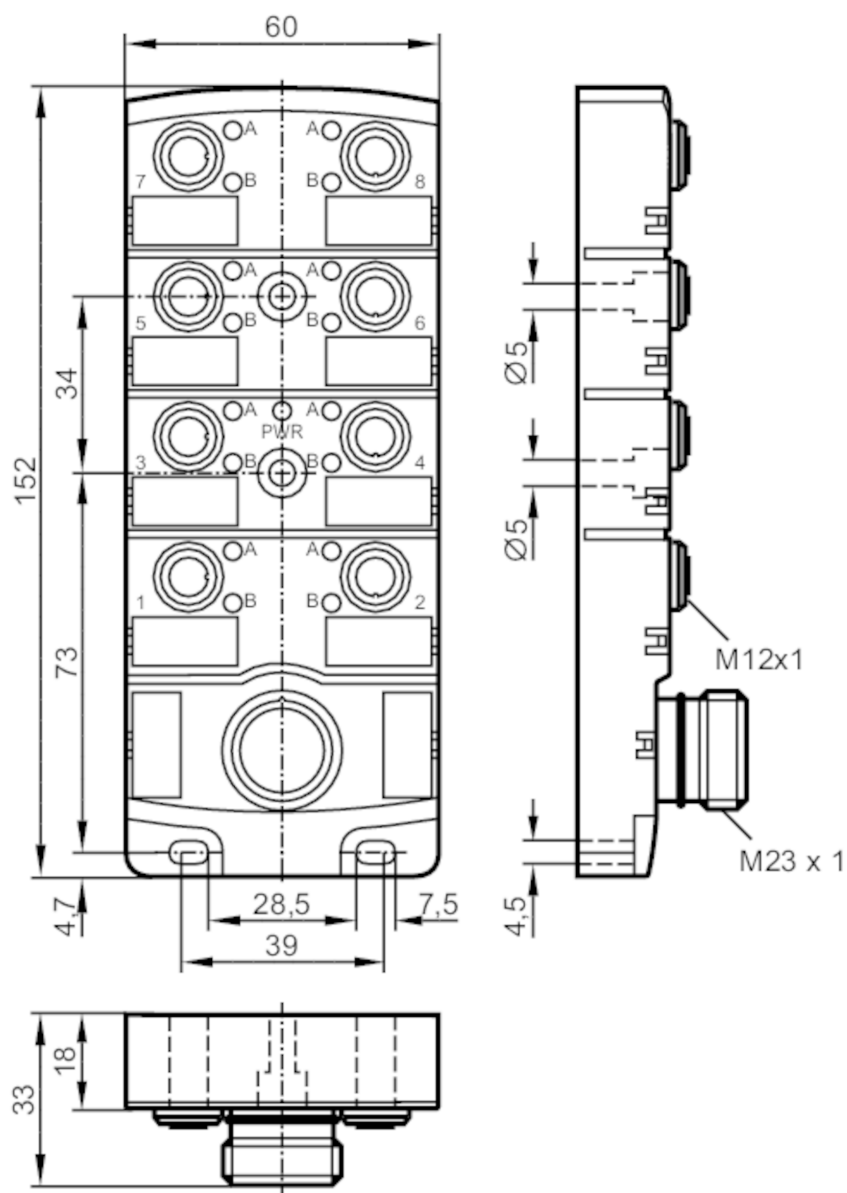

ja

10...30 DC; ("supply class 2" iht. cULus)

4


10

PNP



## Splitterboks


ZDO8H05HMSS0000-00STAK190MSS
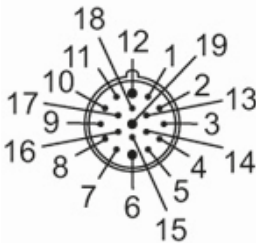
| Omgivende forhold                                                                     |                |                                   |
|---------------------------------------------------------------------------------------|----------------|-----------------------------------|
| Omgivelsestemperatur                                                                  | [°C]           | -25...80                          |
| Kapslingsklasse                                                                       |                | IP 67                             |
| Godkendelser / Tests                                                                  |                |                                   |
| UL godkendelse                                                                        | Enclosure type | Type 1                            |
| Mekaniske data                                                                        |                |                                   |
| Vægt                                                                                  | [g]            | 306                               |
| Dimensioner                                                                           | [mm]           | 33 x 60 x 152                     |
| Materiale                                                                             |                | PA                                |
| Indstøbt-emne materiale                                                               |                | PA                                |
| Antal porte på splitterboks                                                           |                | 8                                 |
| Stiktype                                                                              |                | M12                               |
| Display / Betjeningsenhed                                                             |                |                                   |
| Display                                                                               | udgangs status | 16 x LED, gul                     |
|                                                                                       | Drift          | 1 x LED, grøn                     |
| Tilbehør                                                                              |                |                                   |
| Leverings omfang                                                                      |                | Beskyttelseshætte: 2<br>mærker: 8 |
| Bemærkning                                                                            |                |                                   |
| Emballage-enheder                                                                     |                | 1 stk.                            |
| Elektrisk tilslutning - Tilslutning                                                   |                |                                   |
| Stik: 1 x M23; Støbt hus: PA; Kontakter: guldbelagt; tilspændingsmoment: 0,8...1,5 Nm |                |                                   |
|    |                |                                   |

## Splitterboks

ZDO8H05HMSS0000-00STAK190MSS

## Tilslutning

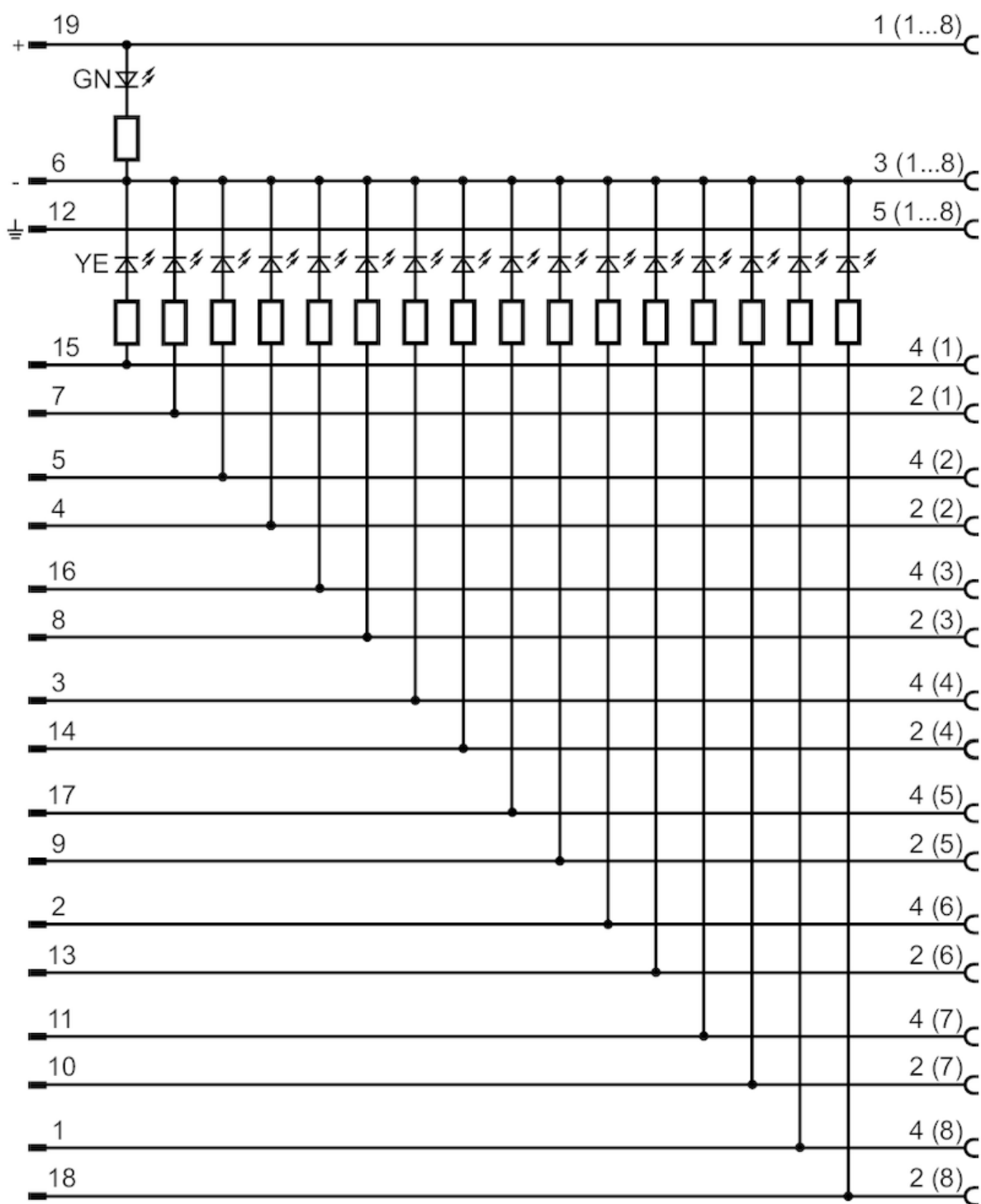



## Splitterboks

ZDO8H05HMSS0000-00STAK190MSS

### Elektrisk tilslutning - slids

Stik: 8 x M12; kodning: A; Støbt hus: PA; Kontakter: guldbelagt; tilspændingsmoment: 0,8...1,5 Nm

