

ORS-V/10m

Alternative artikler: OR0003

Technical drawing of a mechanical part showing front and side views with dimensions.

Front View (Left):

- Overall width: 10
- Overall height: 25
- Distance from top edge to the center of the circular feature: 9
- Bottom flange thickness: 3

Side View (Right):

- Overall width: 15
- Distance from the left edge to the center of the circular feature: 3
- Distance from the center of the circular feature to the right edge: 3.2
- Distance from the top edge to the center of the circular feature: 3
- Distance from the center of the circular feature to the bottom edge: 19
- Bottom flange thickness: 3

EMC	EN 60947-5-2	
-----	--------------	--



Thru-beam sensor (sender)

ORS-V/10m

MTTF	[År]	57078
------	------	-------

Mekaniske data

Vægt	[g]	0,129
Kapsling		rektangulær
Materiale		PPO modificeret
Linse orientering		Optik i siden

Tilbehør

Leverings omfang	Vinkel beslag: 1, E20212
------------------	--------------------------


Bemærkning

Emballage-enheder	1 stk.
-------------------	--------

Elektrisk tilslutning

Kabel: 10 m; 1 x 0,14 mm ²

Tilslutning

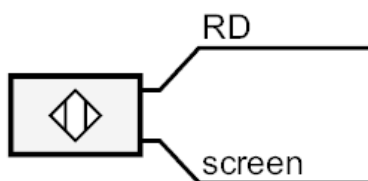

RD =	Ledningsfarver :
screen =	rød
	Skærm