

AC2001




AS-Interface module

ASI-MODUL-OBERTEIL M12 4E100mA

Article no longer available - archive entry

Alternative article: AC5205 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

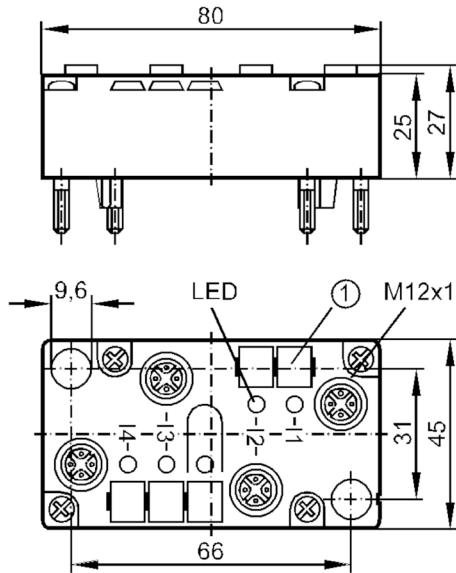

1 panel for labelling



Electrical data		
Operating voltage	[V]	26.5...31.6 DC
Current consumption	[mA]	< 135
Inputs / outputs		
Number of inputs and outputs	Number of digital inputs: 4	
Inputs		
Number of digital inputs	4	
Input circuit of digital inputs	PNP	
Sensor supply of the inputs	AS-i	
Voltage supply	[V]	20...30
Max. total current rating of inputs	[mA]	100
Input current High	[mA]	> 5
Input current Low	[mA]	< 1.5
Min. switching level high signal	[V]	10
Digital inputs protected against short circuits	yes	
Outputs		
Electrical design	AS-i	

AC2001



AS-Interface module

ASI-MODUL-OBERTEIL M12 4E100mA

Operating conditions				
Ambient temperature	[°C]		-25...85	
Protection			IP 67	
Tests / approvals				
EMC		EN 50295		
AS-i classification				
AS-i profile			S-0.0	
AS-i I/O configuration	[hex]		0	
AS-i ID code	[hex]		0	
Assignment of the data bits				
	data bit	D0	D1	D2
	socket	I-1	I-2	I-3
	pin	2+4	2+4	3+4
				3+4
Mechanical data				
Type of mounting		AS-i interface to FC and SC lower parts		
Materials		PBT		
Displays / operating elements				
Display	operation		LED, green	
	function		LED, yellow	
Remarks				
Pack quantity		1 pcs.		
Electrical connection				
contact pins to module lower part, FK / PG:				
Connector: M12				



Article no longer available - archive entry

Alternative article: AC5205 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!