


# E10829



## Connecting cable with socket

ADOGH040MSS0005F04

Article no longer available - archive entry

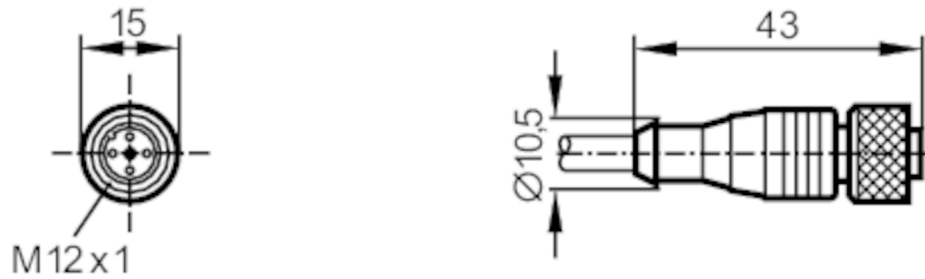

### Electrical data

Operating voltage [V] < 250 AC / < 300 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Dimensions [mm] 15 x 15 x 43

Materials TPU

Material nut brass, nickel-plated

### Remarks

 
Pack quantity 1 pcs.

### Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; cross-linked; 4 x 0.34 mm<sup>2</sup> (19 x Ø 0.15 mm)

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated




# E10829



## Connecting cable with socket

ADOGH040MSS0005F04

### Connection

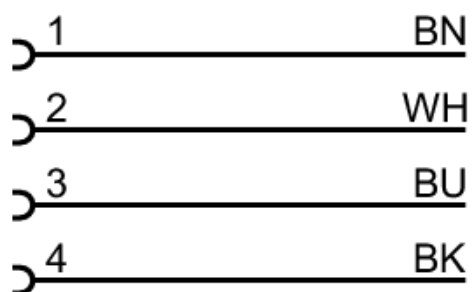

Core colours :

BK = black  
BN = brown  
BU = blue  
WH = white

Article no longer available - archive entry