

# E11488



## Connecting cable with socket

ADOGF030MSS0010H03

Article no longer available - archive entry

replaced by: EVC143



Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Dimensions [mm]	10 x 10 x 31
Materials	PUR
Material nut	brass, nickel-plated / brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

# E11488



## Connecting cable with socket

ADOGF030MSS0010H03

### Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )


### Electrical connection - socket

Connector: 1 x M8, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



### Connection

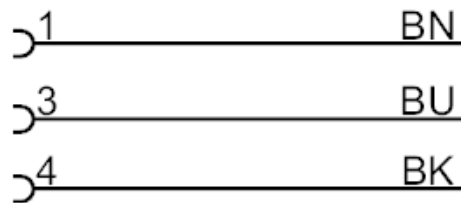

Core colours :

BK = black  
BN = brown  
BU = blue

Article no longer available - archive entry

replaced by: EVC143