

# E11107




## Connection cable

VDOAH040MSS0001E04STGH040MSS

Article no longer available - archive entry

Alternative article: EVC017 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

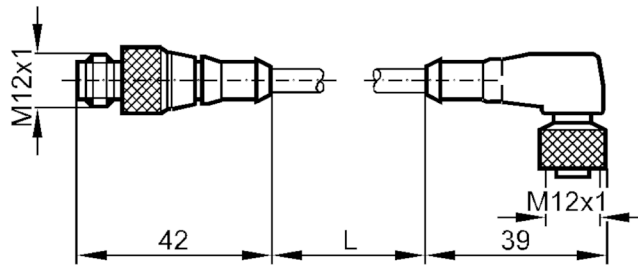

### Electrical data

Operating voltage [V] < 250 AC / < 300 DC

### Operating conditions

Ambient temperature [°C] -25...70

Protection IP 67

### Mechanical data

Materials TPU

Material nut brass, nickel-plated / brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated



# E11107




## Connection cable

VDOAH040MSS0001E04STGH040MSS

### Electrical connection

Cable: 1 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Connection

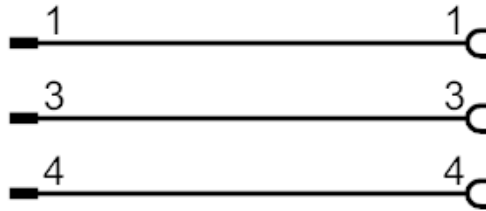

### Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated



Article no longer available - archive entry

Alternative article: EVC017 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!