



Connecting cable with socket

ADOGF040VAS0005E04

Article no longer available - archive entry

replaced by: EVT135



Application	
Special feature	Free from silicone
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Max. current load total [A]	3
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Dimensions [mm]	10 x 10 x 31
Materials	PVC
Material nut	stainless steel (1.4404 / 316L) / stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm ² (32 x Ø 0.1 mm)	
Electrical connection - socket	
Connector: 1 x M8, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm	
Connector: 1 x M8, straight; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm	

E11223




Connecting cable with socket

ADOGF040VAS0005E04



Connection

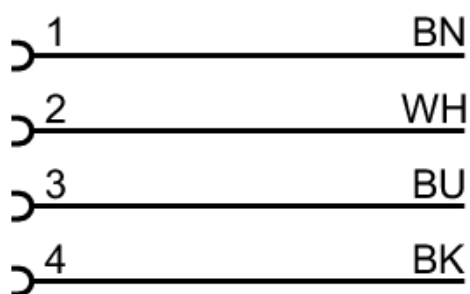

Core colours :

BK = black
BN = brown
BU = blue
WH = white

Article no longer available - archive entry

replaced by: EVT135