

KD5022



Capacitive sensor

KD-3060-BPKG/NI

Accuracy / deviations		
Correction factor	glass: 0.4 / water: 1 / ceramics: 0.2 / PVC: 0.2	
Hysteresis [% of Sr]	1...15	
Switch point drift [% of Sr]	-15...15	
Operating conditions		
Ambient temperature [°C]	-25...50	
Protection	IP 65	
Increased immunity	yes	
Tests / approvals		
EMC	EN 60947-5-2	
MTTF [years]	615	
Mechanical data		
Weight [g]	405	
Housing	rectangular	
Mounting	non-flush mountable	
Dimensions [mm]	120 x 80 x 30	
Materials	PPE modified	
Displays / operating elements		
Display	switching status	1 x LED, yellow
Accessories		
Accessories (supplied)	screwdriver: 1	
Remarks		
Pack quantity	1 pcs.	

KD5022




Capacitive sensor

KD-3060-BPKG/NI

Electrical connection

Cable: 2 m, PVC; 3 x 0.5 mm²

Connection

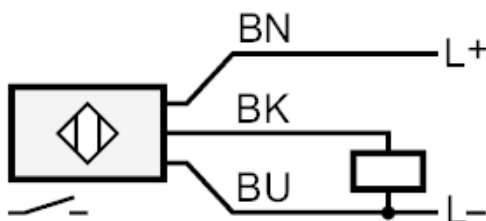

Core colours :

BN =

brown

BK =

black

BU =

blue