


# E3M132

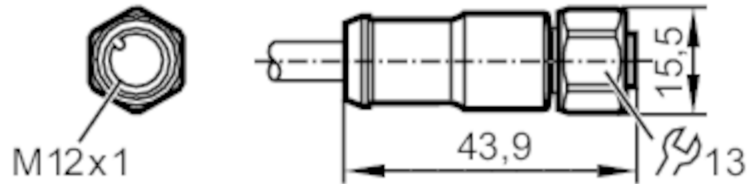

## Connecting cable with socket

POWER SUPPLY CABLE O3M ILLUMINATION 5M



### Application

Special feature Gold-plated contacts; Drag chain suitability

### Electrical data

Operating voltage [V] < 25 AC / < 60 DC

### Operating conditions

Ambient temperature [°C] -40...85

Protection IP 68

### Mechanical data

Weight [g] 309.7

Dimensions [mm] 15.5 x 15.5 x 43.9

Materials PUR

Moulded-body material PUR

Material nut diecast zinc

Drag chain suitability yes

Drag chain suitability bending radius for fixed installation  $\geq 30$  mm

### Remarks

Pack quantity 1 pcs.

# E3M132



## Connecting cable with socket


POWER SUPPLY CABLE O3M ILLUMINATION 5M

### Electrical connection

Cable: 5 m, PUR, black, Ø 6 mm; 4 x 0.75 mm<sup>2</sup>

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: diecast zinc; Contacts: gold-plated

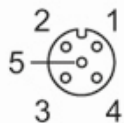

### Connection

