


Adapter plug

ESTGH040MSS0,05E04 (PG13,5)

Article no longer available - archive entry

Alternative articles: E11293

When selecting an alternative article and accessories please note that technical data may differ!

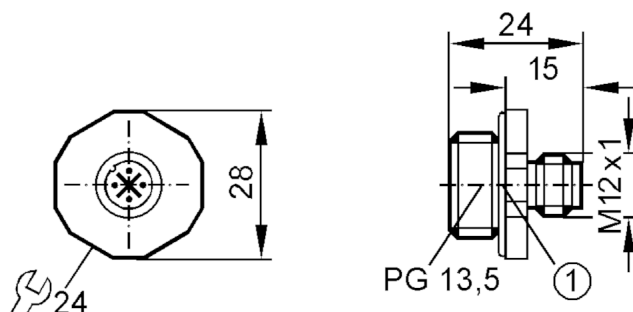

1 O-ring

Electrical data

Operating voltage	[M]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 67

Mechanical data

Mounting thread	PG 13.5
Materials	brass nickel-plated
Moulded-body material	brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E10406



Adapter plug

ESTGH040MSS0,05E04 (PG13,5)

Electrical connection

Cable: 0.05 m, PVC; 4 x 0.34 mm²

Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white