


Connecting cable with socket

ADOAH040VAS0010E03

Article no longer available - archive entry

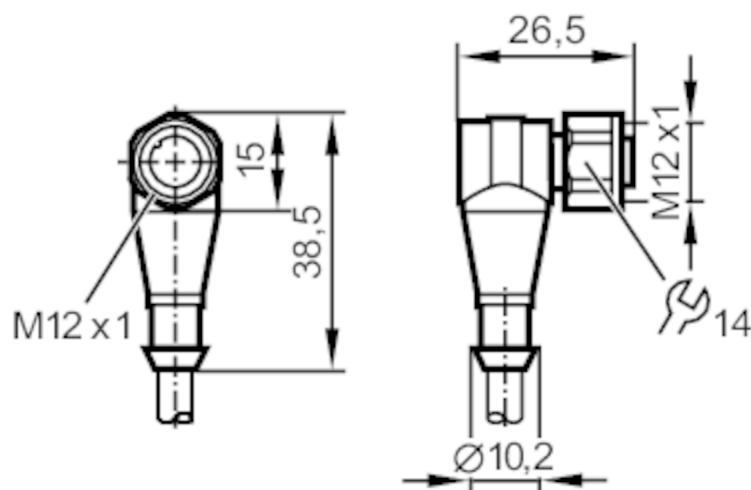

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 250 AC / < 300 DC

Operating conditions

Ambient temperature

[°C]

-25...70

Protection

IP 67

Mechanical data

Dimensions

[mm]

26.5 x 15 x 38.5

Materials

PVC

Moulded-body material

PVC

Material nut

stainless steel (316L/1.4404)

Remarks

Pack quantity

1 pcs.

E10739



Connecting cable with socket

ADOAH040VAS0010E03

Electrical connection


Cable: 10 m, PVC, orange, Ø 3.5 mm; 3 x 0.14 mm² (72 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Contacts: gold-plated



Connection

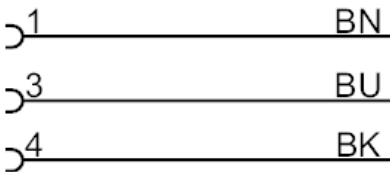

BK = Core colours :
BN = black
BU = brown
 blue