

E10861




Connecting cable with socket

ADOAF040MSS0002E04

Article no longer available - archive entry

Alternative articles: E11220
When selecting an alternative article and accessories please note that technical data may differ!

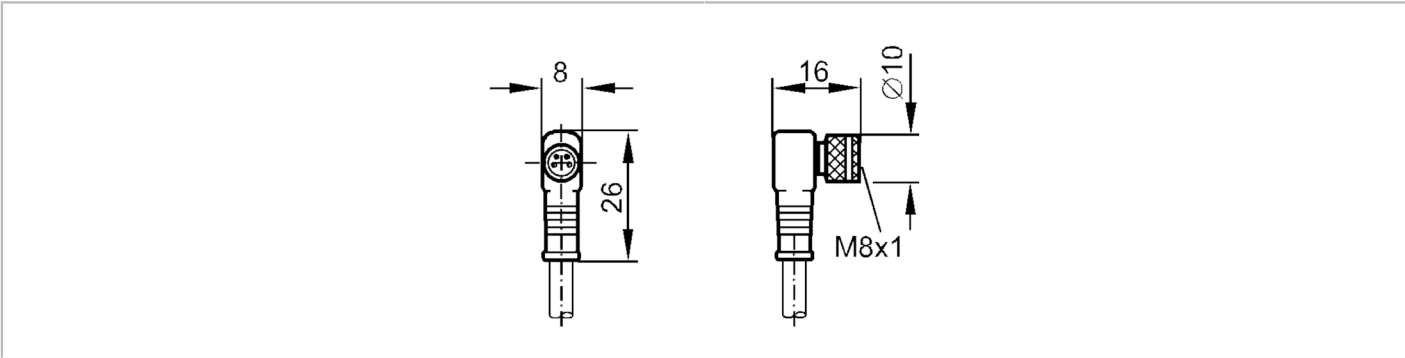

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67; (if screwed on)

Mechanical data

Dimensions	[mm]	16 x 8 x 26
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 2 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

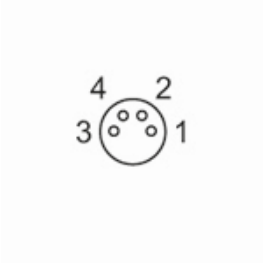

E10861



Connecting cable with socket

ADOAF040MSS0002E04

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white